


- Flanged chloroprene elastomer moulded into a nut

Advantages

- Cost effective
- Isolation of noise and resonance
- Oil, fats, and ozone-resistant
- Simple and tool free installation
- Can be mounted in:
Compression - shearing
Compression/shearing
- Working temperature range: -30°C to +80°C
- Isolated vibrations from 120 to 150Hz

Info.

- Not sold individually,
please contact us for details

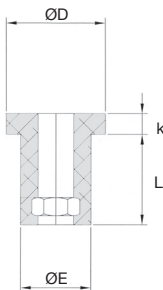

Mounting type 1



Mounting type 2

DISCOUNTS

Qty	1+	13+	29+	41+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Thread	ØD	ØE	L	K	Stock*	Price each 1 to 12
ECF3	M3	9	7,2	9,0	2,5	✓	1,74 €
ECF4	M4	12	9,3	11,5	3,0	✓	1,92 €
ECF5	M5	15	10,2	14,5	3,5	✓	2,22 €
ECF6	M6	18	12,7	17,0	4,0	✓	2,48 €
ECF8	M8	24	16,6	22,0	5,0	✓	2,75 €

*Depending on availability - Dimensions in mm

Our other products




SSB
Stainless steel bevel gear, 1:1



WJUM20
Drylin® W bearing block, Slide



 CLA
Clamping lever Hygienic Usit® - female, Stainless steel



NRR
Adjustable support clamp, Adjustable support clamp



CHML63
Worm and wheel gear reducer, up to 138 Nm - Integrated torque limiter



ACLEPP
Right angled bracket for aluminium profile, 4 holes



ACLBMC
Detector support for aluminium profile, Sensor holder



PO
Pull handle - Multi-sector, Smooth hole



BLH20
Right angled gearbox, from 0.53 to 1.77



AF
Shaft clamp with keyway, Set screw



PRF_CLIP_22
Cable clip for aluminium profile, For electric and



PP35
Worm and wheel gear reducer, from 2.20 to 4.10 Nm

Complementary products