

- Flanged chloroprene elastomer moulded into a nut


Advantages

- Cost effective
- Isolation of noise and resonance
- Oil, fats, and ozone-resistant
- Simple and tool free installation
- Can be mounted in:
 - Compression - shearing
 - Compression/shearing
- Working temperature range: -30°C to +80°C
- Isolated vibrations from 120 to 150Hz



Info.

- Not sold individually, please contact us for details

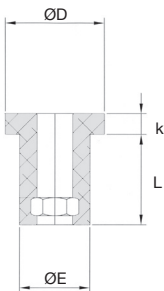

Mounting type 1



Mounting type 2

DISCOUNTS

Qty	1+	13+	29+	41+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Thread	ØD	ØE	L	K	Stock*	Price each 1 to 12
ECF3	M3	9	7,2	9,0	2,5	✓	1,74 €
ECF4	M4	12	9,3	11,5	3,0	✓	1,92 €
ECF5	M5	15	10,2	14,5	3,5	✓	2,22 €
ECF6	M6	18	12,7	17,0	4,0	✓	2,48 €
ECF8	M8	24	16,6	22,0	5,0	✓	2,75 €

*Depending on availability - Dimensions in mm

Our other products




Masterplate® glueable insert
Ø19/Ø20, Cylindrical with nut



Stainless steel spherical bearing,
Stainless steel / PTFE



Right angled gearbox,
from 11.50 to 30 Nm

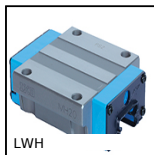

High rigidity linear slide, Chariot - from
9320 N to 71300 N



Stainless steel/Polymer flanged bearing,
Polymer and stainless steel



End cap for round tube, Standard



Male clevis end, Steel short



 
Miniature motorised actuator 1A, 1 amper



T type timing belt,
T2.5 Steel cored polyurethane



Universal fastener for aluminium profile,
Universal



Automatic chain tensioner, With 180° guide



Box set of washer - DIN125, Box set of steel washers

Complementary products