

- Flanged chloroprene elastomer moulded into a nut


Advantages

- Cost effective
- Isolation of noise and resonance
- Oil, fats, and ozone-resistant
- Simple and tool free installation
- Can be mounted in:
 - Compression - shearing
 - Compression/shearing
- Working temperature range: -30°C to +80°C
- Isolated vibrations from 120 to 150Hz



Info.

- Not sold individually, please contact us for details

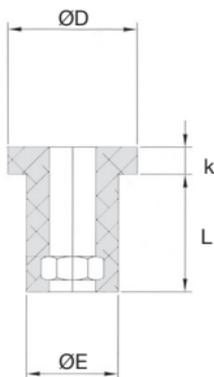

Mounting type 1



Mounting type 2

DISCOUNTS

Qty	1+	13+	29+	41+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Thread	ØD	ØE	L	K	Stock*	Price each 1 to 12
ECF3	M3	9	7,2	9,0	2,5	✓	1,74 €
ECF4	M4	12	9,3	11,5	3,0	✓	1,92 €
ECF5	M5	15	10,2	14,5	3,5	✓	2,22 €
ECF6	M6	18	12,7	17,0	4,0	✓	2,48 €
ECF8	M8	24	16,6	22,0	5,0	✓	2,75 €

*Depending on availability - Dimensions in mm

Our other products



SSG1
Stainless steel spur gear, Stainless steel 304L



GDR880
Straight track for slat top chain, Ranges 880 and 881



BZY_SS
Stainless steel cylindrical elasto mount, Stainless steel



BEAS
Star shaped anti-static handle, Star, anti-static



BOX-TOR-DRING
Box set of Nitrile D-rings NBR90Sh A, Flange seals



PCS62K
Chain sprocket with hardened teeth, 15.875mm (DIN10B-1)



SLVVlok
Vertical toggle clamp, Vertical toggle clamp / vertical foot



SRG
Adjustable latch clamp with strike plate, Stroke from 77,3mm to 83mm



NCT
Square tube connector, Fixed



TS01_TW01
Drylin® T linear slide, up to 7000 N



SNG
Stainless/Polymer pillow block bearing,



M1
Worm, Machined plastic (delrin)

Complementary products