

- Flanged chloroprene elastomer moulded into a nut


Advantages

- Cost effective
- Isolation of noise and resonance
- Oil, fats, and ozone-resistant
- Simple and tool free installation
- Can be mounted in:
 - Compression - shearing
 - Compression/shearing
- Working temperature range: -30°C to +80°C
- Isolated vibrations from 120 to 150Hz



Info.

- Not sold individually, please contact us for details

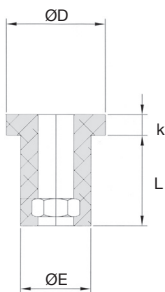

Mounting type 1



Mounting type 2

DISCOUNTS

Qty	1+	13+	29+	41+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Thread	ØD	ØE	L	K	Stock*	Price each 1 to 12
ECF3	M3	9	7,2	9,0	2,5	✓	1,74 €
ECF4	M4	12	9,3	11,5	3,0	✓	1,92 €
ECF5	M5	15	10,2	14,5	3,5	✓	2,22 €
ECF6	M6	18	12,7	17,0	4,0	✓	2,48 €
ECF8	M8	24	16,6	22,0	5,0	✓	2,75 €

*Depending on availability - Dimensions in mm

Our other products



PSP
Support profile, Panel support



CHAR5050_Z
Spring hinge, screwed



ZBconique
Machined plastic bevel gear , 1:1



GGB
Female wing knob, With blind thread



LWH
High rigidity linear slide, Rail - from 9320 N to 71300 N



INS
Self tapping steel insert, Steel



PCS50
Chain sprocket - steel, 12.7mm (DIN08B-1)



METC
Flanged sintered bronze bush, Self-lubricating sintered bronze



PW_PWG3
Worm - precision range, Stainless steel



PRF_PL_9090
Joining plate for aluminium profile, Joint plate - 90x90 mm



PTRSS
Idle chain sprocket, For hostile environments



MSP3815
Masterplate® glueable insert rectangular, rectangular with threaded...

Complementary products