

- Flanged chloroprene elastomer moulded into a nut


Advantages

- Cost effective
- Isolation of noise and resonance
- Oil, fats, and ozone-resistant
- Simple and tool free installation
- Can be mounted in:
 - Compression - shearing
 - Compression/shearing
- Working temperature range: -30°C to +80°C
- Isolated vibrations from 120 to 150Hz



Info.

- Not sold individually, please contact us for details

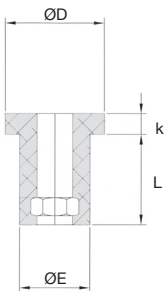

Mounting type 1



Mounting type 2

DISCOUNTS

Qty	1+	13+	29+	41+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Thread	ØD	ØE	L	K	Stock*	Price each 1 to 12
ECF3	M3	9	7,2	9,0	2,5	✓	1,74 €
ECF4	M4	12	9,3	11,5	3,0	✓	1,92 €
ECF5	M5	15	10,2	14,5	3,5	✓	2,22 €
ECF6	M6	18	12,7	17,0	4,0	✓	2,48 €
ECF8	M8	24	16,6	22,0	5,0	✓	2,75 €

*Depending on availability - Dimensions in mm

Our other products



NT91
Spur gear coaxial gearbox, from 10 to 35 Nm - Inline



PCS62K
Chain sprocket with hardened teeth, 15.875mm (DIN10B-1)



G-ECO
Eco range Spur gear, Steel C45



BSM_LOK
Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



RLXAC8
Free roller, Steel



FUSS
Bearing locknut, Self locking locknut - stainless steel lock washer



TK_UUOP
Topball self-aligning linear bearing, Topball self-aligning



FTSN
Supported shaft for linear guide, Steel shaft / Aluminium support



SLB
Indexing plunger, stainless steel



PR65C
Half-articulated foot \varnothing 65, \varnothing 65



YG1
HEAVY DUTY spur gear, Steel 35NCD6



TPEpb
Castor for aluminium profile, Swivel with brake

Complementary products