

- Flanged chloroprene elastomer moulded into a nut


Advantages

- Cost effective
- Isolation of noise and resonance
- Oil, fats, and ozone-resistant
- Simple and tool free installation
- Can be mounted in:
 - Compression - shearing
 - Compression/shearing
- Working temperature range: -30°C to +80°C
- Isolated vibrations from 120 to 150Hz



Info.

- Not sold individually, please contact us for details

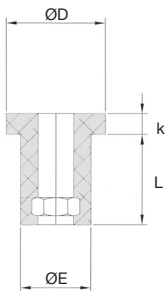

Mounting type 1



Mounting type 2

DISCOUNTS

Qty	1+	13+	29+	41+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Thread	ØD	ØE	L	K	Stock*	Price each 1 to 12
ECF3	M3	9	7,2	9,0	2,5	✓	1,74 €
ECF4	M4	12	9,3	11,5	3,0	✓	1,92 €
ECF5	M5	15	10,2	14,5	3,5	✓	2,22 €
ECF6	M6	18	12,7	17,0	4,0	✓	2,48 €
ECF8	M8	24	16,6	22,0	5,0	✓	2,75 €

*Depending on availability - Dimensions in mm

Our other products



HTD5M_25
HTD Heavy duty timing pulley, HTD5 Aluminium



GG2
Ground spur gear, Heat treated steel



 
PHT
Pull handle, Up to 250 °C



RESC
Retractable castor for aluminium profile, Retractable castor



AK
Bellows coupling Gerwah®, from 36 to 800Nm



M0
Worm and wheel set, Machined plastic (delrin)



PCF4
Conical flexible mount, Square base plate



ADL_F
Female eye bolt conforms to DIN582, Steel



CHAR5050_Z
Spring hinge, screwed



CHTRB
Single and dual output gearboxes, Up to 53,1 Nm



BLHB60
Right angled gearbox, bored shafts, up to 70 Nm



DER80
Stainless steel AC asynchronous motor 0.55 - 0.75kW, 0.55 to 0.75kW

Complementary products