

- Flanged chloroprene elastomer moulded into a nut



### Advantages

- Cost effective
- Isolation of noise and resonance
- Oil, fats, and ozone-resistant
- Simple and tool free installation
- Can be mounted in:
  - Compression - shearing
  - Compression/shearing
- Working temperature range: -30°C to +80°C
- Isolated vibrations from 120 to 150Hz



### Info.

- Not sold individually, please contact us for details

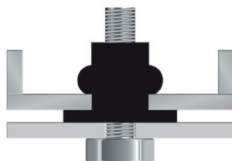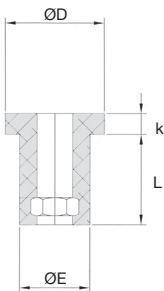

Mounting type 1



Mounting type 2

### DISCOUNTS

Qty	1+	13+	29+	41+	60+
Disc.	List	-10%	-15%	-20%	On request

Part number	Thread	ØD	ØE	L	K	Stock*	Price each 1 to 12
ECF3	M3	9	7,2	9,0	2,5	✓	1,74 €
ECF4	M4	12	9,3	11,5	3,0	✓	1,92 €
ECF5	M5	15	10,2	14,5	3,5	✓	2,22 €
ECF6	M6	18	12,7	17,0	4,0	✓	2,48 €
ECF8	M8	24	16,6	22,0	5,0	✓	2,75 €

\*Depending on availability - Dimensions in mm

## Our other products



CABtool

Fitting cable tools,  
Crimping tools



BIMSS

Indexing plunger mini,  
miniature - Stainless  
steel



MPB

Hexagonal spacer,  
Brass



H1

Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



STRIP1000

Sealing brush strip,  
1m length



CM\_CO

Tools Hygienic Usit®  
and Hygienic  
Design®, Protective  
inserts for ...



HTD8M\_50

HTD Heavy duty  
timing pulley, HTD8  
Steel



BABtss

303 Stainless steel  
ball pin, 303 Stainless  
steel



BCAss

Stainless steel splined  
bush, Inox



PW\_PWG25

Wheel - precision  
range, Bronze



PTRSS

Idler chain sprocket,  
For hostile



SFWR

End support, Surface  
mounting

Complementary products