 

 
 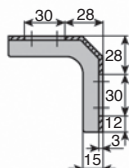

 



- Material:
stainless
steel

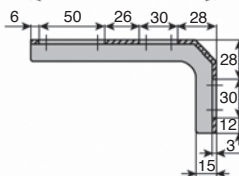

EDS-70



EDS-140

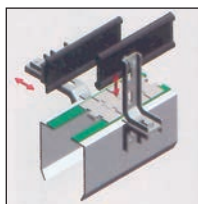

Typical application

DISCOUNTS

Qty	1+	10+	20+
Disc.	List	-5%	On request

Part number	L	Weight (kg)	Stock*	Price each 1 to 9
EDS-70	70	0,15	✓	19,42 €
EDS-140	140	0,24	✓	23,55 €

*Depending on availability - Dimensions in mm

Our other products



CHM30-MOT
Asynchronous AC
motorgearboxes 0.09
to 0.22kW, 0.09 to
0.22kW



BPM_LOK
Long-Lok slotted
spring plunger, LONG-
LOK - Stainless steel
303



SSDB
Stainless steel bevel
gear, 2:1



MFBSC
Stainless steel flexible
bellows coupling,
Stainless steel - with
cl...



PRFSRAD
Dual lock for use on
aluminium profile,
Quick fitting, self
locking ...



VTH
Hexagonal headed
bolts, Steel class 8.8



CLG1
Moulded plastic spur
gear, Moulded plastic
(nylon)



PGMram
Carrying handle
Hygienic Usit®,
Stainless steel
support washer



SBS_L
Chain link, Stainless
steel



OP3_14_06
Reducing sleeve for
OP indicators,
Reduction socket



BTC20_10
End cap for
rectangular tube,
Standard



CQA20
Accessory for
adjustment slide-
system, 20

Complementary products