 

 
 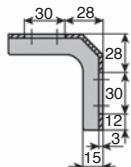

 



- Material:  
stainless  
steel

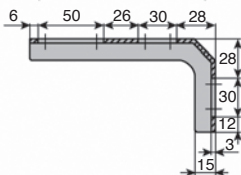

EDS-70



EDS-140

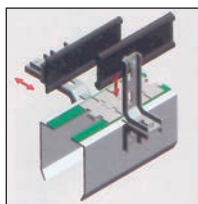

Typical application

### DISCOUNTS

Qty	1+	10+	20+
Disc.	List	-5%	On request

Part number	L	Weight (kg)	Stock*	Price each 1 to 9
EDS-70	70	0,15	✓	19,42 €
EDS-140	140	0,24	✓	23,55 €

\*Depending on availability - Dimensions in mm

## Our other products




PTRSS

Idler chain sprocket,  
For hostile  
environments



WJUM20

Drylin® W modular  
guidance, Slide

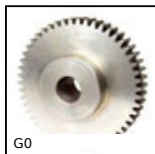

G0

Spur gear, Steel  
20NCD2



HS

Spacer, Stainless steel  
303



PRF\_TOOL

Tools, Assembly key



SRG

Adjustable latch  
clamp with catch-  
plate, Stroke from  
117,4mm to 128mm



PAMF100

Articulated fixable  
foot with pressed  
base, Ø 100



CHAR7520

Spring hinges,  
screwed



 
HDSS

Universal joint -  
stainless steel, Needle  
bearings - double



BEAB

Knob for clamping,  
Star, anti-bacterial



CHMR110

Worm and wheel  
gearbox, up to 980  
Nm



SLB

Indexing plunger,  
stainless steel

Complementary products