
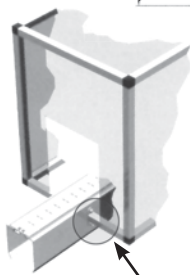


- Support for square section tube
- Material: stainless steel 304

Accessories

- Connecting joint NCT
- Tube TUBE25-25

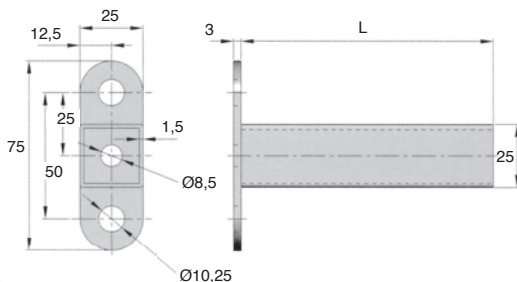

Typical application

DISCOUNTS

Qty	1+	10+	21+
Disc.	List	-5%	On request

Part number	L	Weight (kg)	Stock*	Price each 1 to 9
EFTC25-50/SS	50	0,09	✓	9,95 €
EFTC25-100/SS	100	0,15	-	10,76 €
EFTC25-150/SS	150	0,20	✓	11,72 €


*Depending on availability - Dimensions in mm

Our other products




WW10

 Drylin® W slide, slide assembly



LVTMFC

 Device for controlling limit switches, For mini-actuator LVT



EPRF

High helix leadscrew, Flanged nut - up to 40mm per rotation



SDG

Adjustable guide support bracket, Plastic



DOG319

Motor-gearbox 12V and 24V DC, from 4 to 9 Nm



BLHT20

Right angled gearbox, from 0.66 to 1.77 Nm



RFK38B

Hypoid gearbox - Stainless steel, up to 200 Nm



BEAB

Knob star grip antibacterial, Star, anti-bacterial



BAP

Plastic clamping collar, $\varnothing 10 - \varnothing 20$



SH3

Parallel axis helical gear, Steel 20NCD2



DCG

Suction cup, 2.5 bellows, silicon



PTGR

Tensioner pulley, For round belts

Complementary products



TUBE25_25

Square Tube, Aluminium or Stainless steel