

# Tee nuts with pronge

## EGRM

## Steel


- Socket nut that easily inserts into soft materials
- Remains in place without turning
- Material :  
Steel zinc plated

### Advantages

- Tee nuts with pronge increase clamping quality in soft materials (wood, panels, chipboard, plastics)
- Repeated tightening without damaging the surface

### Info

- Sold by the packet

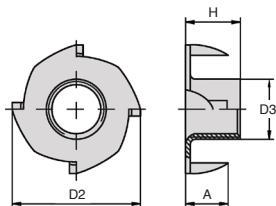

### DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-10%	On request

Part number	Thread ØM	ØD2	ØD3	H	A	Qty per packet	Price per packet
EGRM4-6/B	M4	15	5	6	5	200	
EGRM5-8/B	M5	17	6,5	8	7	200	
EGRM6-9/B	M6	19	7,5	9	7	200	
EGRM6-12/B	M6	19	7,5	12	8	200	
EGRM8-11/B	M8	22	10	11	9	100	
EGRM8-15/B	M8	22	10	15	10	100	
EGRM10-13/B	M10	25	11,5	13	11	100	

Dimensions in mm

## Our other products




YG2

HEAVY DUTY spur gear, Steel 35NCD6



ARTE

 Flexible bush, For multi-directional loads



G1

Steel spur gear, Steel 20NCD2



CHAM5270SS

Marine hinge for welding/screw mounting, Marine



RAS

90° ball and socket joints DIN71802, Steel



VELM6

Screw-on base for hook-and-loop strip, Polyamide



SPIT

Floor mounting levelling plate, With anchoring point



MSP3815

Masterplate® glueable insert rectangular, rectangular with



DOMI120

Accessories, Plate



KB\_WW

Closed linear precision bearing, Economy range



TPEf

Castor for aluminium profile, Fixed



NKXR

Combined bearing without inner ring, Needle and cylindrical rollers

Complementary products