
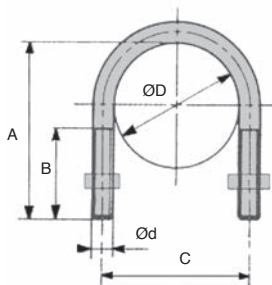
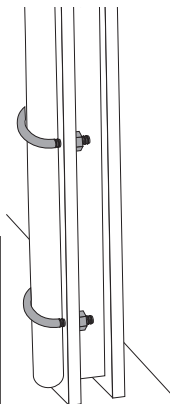


- Drawn steel wire, tolerance h9, overall tolerance 10
- 2 hexagonal nuts
- Material:
Stainless steel 304

Stainless steel

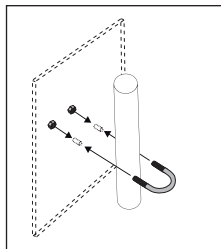

DISCOUNTS

Qty	1+	101+	201+	301+	401+
Disc. Prix	-5%	-10%	-15%	On request	


Part number	For tubr		Filet Ød	A (mm)	B (mm)	C (mm)	Stock*	Price each 1 to 100
	ØE external ØD	Ø internal d						
EIM013	13	1/4	M6	28	20	19	-	1,19 €
EIM017	17	3/8	M6	36	22	23	-	1,44 €
EIM021	21	1/2	M6	40	20	27	✓	1,51 €
EIM027	27	3/4	M8	50	30	35	✓	2,77 €
EIM034	34	1	M8	55	30	42	✓	3,03 €
EIM042	42	1 ^{1/4}	M8	68	35	50	✓	3,43 €
EIM049	49	1 ^{1/2}	M8	70	35	57	✓	3,55 €
EIM060	60	2	M8	80	35	68	✓	3,68 €
EIM076	76	2 ^{1/2}	M8	110	45	84	-	4,43 €
EIM089	89	3	M10	115	45	99	-	7,96 €
EIM114	114	4	M10	156	55	124	-	8,98 €

*Depending on availability - Dimensions in mm

Our other products



 
EMS
Stainless steel knurled thumb nut, Knurled



QNJ
Single row cylindrical roller bearing, Single flange on inner ring



 SEV
Vertical stirrup toggle clamp, Vertical Latch Clamp - stainless steel




ACL-PR
Joining plate for aluminium profile, Right angled connection



RBNtc
Swivel castor with central hole, Steel - rubber



BUH77
Motor-gearbox 12V and 24V DC, from 0.1 to 2 Nm

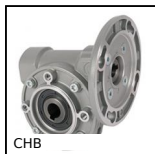

CHB
Worm and wheel gear reducer, up to 22 Nm



G4
Steel spur gear, Steel 20NCD2



PRES7HR
Manual workbench press, Force up to 700kg



SBF
Open flange bearing unit for food industry, cover



V3RA
3-spoked handwheel without handle, Polyamide



PSG2
Spur gear - precision range, Pre-hardened Steel 35NCD6

Complementary products



EBM
Steel U bolt, Steel