
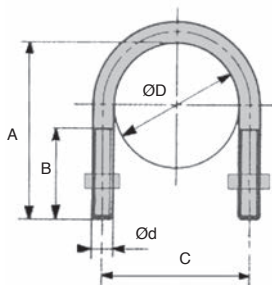
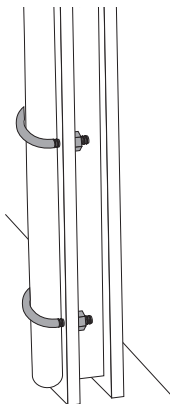


- Drawn steel wire, tolerance h9, overall tolerance 10
- 2 hexagonal nuts
- Material:
Stainless steel 304

Stainless steel

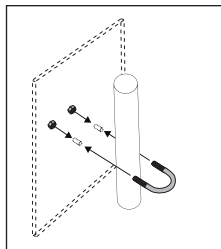

DISCOUNTS

Qty	1+	101+	201+	301+	401+
Disc. Prix	-5%	-10%	-15%	On request	

Part number	For tubr		Filet Ød	A (mm)	B (mm)	C (mm)	Stock*	Price each 1 to 100
	ØE external ØD	Ø internal d						
EIM013	13	1/4	M6	28	20	19	-	1,19 €
EIM017	17	3/8	M6	36	22	23	-	1,44 €
EIM021	21	1/2	M6	40	20	27	✓	1,51 €
EIM027	27	3/4	M8	50	30	35	✓	2,77 €
EIM034	34	1	M8	55	30	42	✓	3,03 €
EIM042	42	1 ^{1/4}	M8	68	35	50	✓	3,43 €
EIM049	49	1 ^{1/2}	M8	70	35	57	✓	3,55 €
EIM060	60	2	M8	80	35	68	✓	3,68 €
EIM076	76	2 ^{1/2}	M8	110	45	84	-	4,43 €
EIM089	89	3	M10	115	45	99	-	7,96 €
EIM114	114	4	M10	156	55	124	-	8,98 €

*Depending on availability - Dimensions in mm

Our other products



Worm and wheel set,
Machined plastic
(delrin)



Stainless steel face
frame hinge, Surface
mount



Eco range Spur gear,
Steel C45



Male rod ends DIN
ISO12240-4, Stainless
steel / bronze -
Economy range




Magnetic stud with
threaded hole, With
threaded hole



Single row cylindrical
roller bearing, 1 fixed
inner flange and 1 fr...



HTD type tooth bar
stock, HTD8

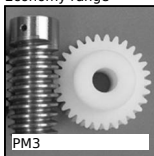

Worm and wheel set,
Machined plastic
(delrin)



Economic mini-table
with trapezoidal



Indexing plunger mini,
miniature - Stainless



Telescopic drawer,



Multifunction display,
Magnetic band

Complementary products



Steel U bolt, Steel