
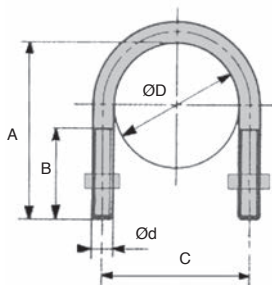
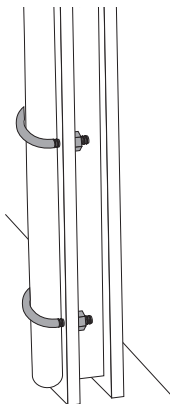


- Drawn steel wire, tolerance h9, overall tolerance 10
- 2 hexagonal nuts
- Material:
Stainless steel 304

Stainless steel

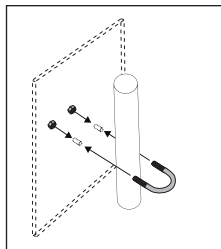

DISCOUNTS

Qty	1+	101+	201+	301+	401+
Disc. Prix	-5%	-10%	-15%	On request	

Part number	For tubr		Filet Ød	A (mm)	B (mm)	C (mm)	Stock*	Price each 1 to 100
	ØE external ØD	Ø internal d						
EIM013	13	1/4	M6	28	20	19	-	1,19 €
EIM017	17	3/8	M6	36	22	23	-	1,44 €
EIM021	21	1/2	M6	40	20	27	✓	1,51 €
EIM027	27	3/4	M8	50	30	35	✓	2,77 €
EIM034	34	1	M8	55	30	42	✓	3,03 €
EIM042	42	1 ^{1/4}	M8	68	35	50	✓	3,43 €
EIM049	49	1 ^{1/2}	M8	70	35	57	✓	3,55 €
EIM060	60	2	M8	80	35	68	✓	3,68 €
EIM076	76	2 ^{1/2}	M8	110	45	84	-	4,43 €
EIM089	89	3	M10	115	45	99	-	7,96 €
EIM114	114	4	M10	156	55	124	-	8,98 €


*Depending on availability - Dimensions in mm

Our other products



PSG25

 Spur gear - precision range, Pre-hardened Steel 35NCD6



KITbuh

24V DC motorisation kit, Planetary gears



SERB

Universal latch key, Universal latch key



CAP805

Slat top chain stainless steel, Large range 805



T39_T49

Extension spring in metre length stainless steel, by the metre



BABFCFO

Ball pin socket, Mounting collar with a round flange



 
CMAss

Eye bolt stainless steel, Stainless steel



CMM

Male rod ends DIN ISO12240-4, Steel / bronze



RPPM

RPP type belt per metre, RPP5 Steel cored polyurethane



MSP23

Masterplate® glueable insert Ø23, Cylindrical Ø23 with



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and



HLUT

Spoked handwheel with handle, Aluminium

Complementary products



EBM

Steel U bolt, Steel