

## D-KONSL

## Male mounting

- Silicone truncated cone form for applications with high hygiene requirements

- Materials:

304 stainless steel frame

Rubber-silicone cone cylinder (Elastosil MVQ)

- Hardness 55+/-5° shoreA

- Working temperature: -30°C to +200°C

### Applications


- End stop

- Supporting foot

- Food industry (FDA compliant), pharmaceutical, medical.

**NEW!**

Stainless steel

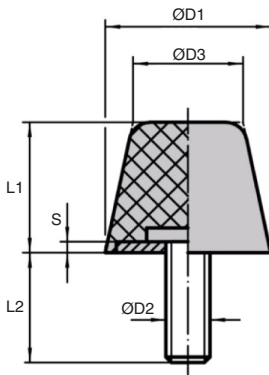

### DISCOUNTS

Qty	1+	4+	15+
Disc. Price	-5%	On request	

Part number	ØD1	ØD2	L2	ØD3	L1	S	R (N/mm)	Stiffness	Max.	Weight		Price each
								load (N)	Stroke	(g)	1 to 3	
D-KON5-19-16/SL	19	M5	20	12,0	16	2	63	250	4,0	10		13,05 €
D-KON6-25-20/SL	25	M6	25	16,5	20,5	2	90	460	5,1	19		13,98 €
D-KON8-32-26/SL	32	M8	30	21,0	26	2	117	760	6,5	38		15,59 €
D-KON8-38-32/SL	38	M8	30	24,5	32	2	113	900	8,0	56		31,12 €
D-KON10-50-43/SL	50	M10	40	32,0	43	2	148	1580	10,7	110		42,57 €

Dimensions in mm



# Silicone conical elast buffer

## Female mounting

## E-KONSL

- Silicone truncated cone form for applications with high hygiene requirements
- Materials:
  - 304 stainless steel frame
  - Rubber-silicone cone cylinder (Elastosil MVQ)
- Hardness 55+/-5° shoreA
- Working temperature: -30°C to +200°C


### Applications

- End stop
- Supporting foot
- Food industry (FDA compliant), pharmaceutical, medical.

**NEW!**



Stainless steel

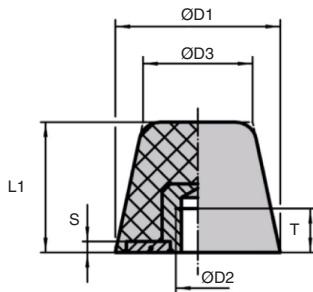

### DISCOUNTS

Qty	1+	4+	15+
Disc.	Price	-5%	On request

Part number	ØD1	ØD2	L2	ØD3	L1	S	R (N/mm)	Max. load (N)	Stroke	Weight (g)	Price each
E-KON5-19-16/SL	19	M5	12,0	16	2	5	63	250	4,0	7	13,49 €
E-KON6-25-20/SL	25	M6	16,5	20,5	2	6	90	460	5,1	14	14,82 €
E-KON8-32-26/SL	32	M8	21,0	26	2	8	117	760	6,5	20	16,77 €
E-KON8-38-32/SL	38	M8	24,5	32	2	8	113	900	8,0	46	32,30 €
E-KON10-50-43/SL	50	M10	32,0	43	2	10	148	1580	10,7	96	44,16 €

Dimensions in mm

## Our other products



HTD5M\_25

HTD Heavy duty timing pulley, HTD5 Steel



SH1

Parallel axis helical gear, Steel 20NCD2



V3RA

3-spoked handwheel without handle, Polyamide



RTL450

Self-centering locking assembly, High torque




NT122

Spur gear coaxial gearbox, from 32 to 85 Nm - In-line



H1

 Crossed helical gear crossed axis at 90°, Steel 20NCD2



RPPM

RPP type belt per metre, RPP8 Steel cored polyurethane



BZY

Cylindrical elasto mount, Steel



PTKFss

Fixable foot for the food industry, Stainless steel - 3-A standard



ACL-PL

Joining plate for aluminium profile, Joint plate - 176x86 mm



PW\_PWG3

Wheel - precision range, Bronze



RURt

Swivel castor with central hole, Polyurethane - Aluminium rim (Free

...

## Complementary products



DKONSL

Silicone conical elasto buffer, Male mounting