

Antistatic knurled nut

EMAS Prevents occurrence of electrostatic spark

Eliminates electrical charges

- Materials :

Reinforced PA thermoplastic, graphite black
Tapped bush in steel trivalent blue passivated

Advantages



- These products can be used for electrostatic discharge applications or areas where electrostatic discharge protection (EPA) in accordance with DIN EN61340-5-1
- The knurled nuts can be tightened or loosened without tools



NEW!



Antistatic

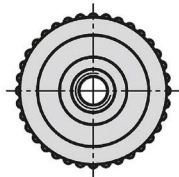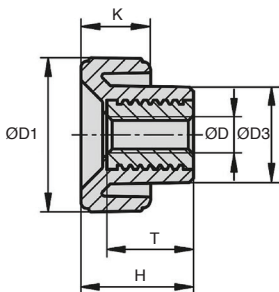

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	ØD1	ØD3	H	K	T	Price each
							1 to 9
EMAS18-M4	M4	18	11	13	8	10	6,12 €
EMAS20-M5	M5	20	13,6	15	9	10	6,61 €
EMAS25-M6	M6	25	14	17	10	10	7,24 €
EMAS32-M8	M8	32	18	22	13	14	8,30 €
EMAS40-M10	M10	40	19	25	14	14	9,03 €

Dimensions in mm

Our other products



HLA28

Right angle spiro bevel gearbox, Up to 182Nm



GG1

Ground spur gear, Heat treated steel



PRF_BR

Clamp for aluminium profile, Clamp for profile



PCS_PA6

Plastic sprocket, 9.525mm (DIN 06B-1)



ACLBMC

Detector support for aluminium profile, Sensor holder



PENC

Recessed handle, clip-in



PGT

Sliding profile, Sliding panel support



EFTC

Fixing support, Stainless steel



UTKswcr

Utilittrak® 3 wheels carriage, Steel roller




M2

Worm and wheel set, Machined plastic



ZG2

 Plastic spur gear, Machined plastic



PX_PO

Carrying handle, standard

Complementary products



BEAS

Star shaped anti-static handle, Star, anti-static



PAS

Pull handle, Reinforced PA thermoplastic



BEAS

Knob star grip antistatic, Star, anti-static