

Antistatic knurled nut

EMAS Prevents occurrence of electrostatic spark

Eliminates electrical charges

- Materials :

Reinforced PA thermoplastic, graphite black
Tapped bush in steel trivalent blue passivated

Advantages



- These products can be used for electrostatic discharge applications or areas where electrostatic discharge protection (EPA) in accordance with DIN EN61340-5-1
- The knurled nuts can be tightened or loosened without tools



NEW!



Antistatic

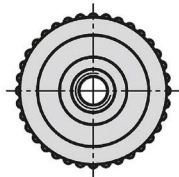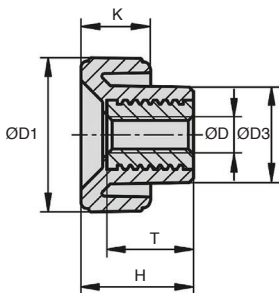

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	ØD1	ØD3	H	K	T	Price each
							1 to 9
EMAS18-M4	M4	18	11	13	8	10	6,12 €
EMAS20-M5	M5	20	13,6	15	9	10	6,61 €
EMAS25-M6	M6	25	14	17	10	10	7,24 €
EMAS32-M8	M8	32	18	22	13	14	8,30 €
EMAS40-M10	M10	40	19	25	14	14	9,03 €

Dimensions in mm

Our other products



ATZYSS
Stainless steel diablo shaped elasto mount,
Stainless steel



H4
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



SLVHlok
Vertical toggle clamp,
Vertical toggle clamp /
horizontal foot



RFK38B
Hypoid gearbox -
Stainless steel, up to
200 Nm



DEP
Tools Hygienic Usit®
and Hygienic
Design®, Protective
insert for s...



BABreceptacle
Ball pin socket, Socket



PSG25
Spur gear - precision
range, Stainless steel
303




NT91
Spur gear coaxial
gearbox, from 10 to
35 Nm - In-line



NPR
Reflector support,



 PSG25
Spur gear - precision
range, Case hardened



PRZ
Wear strip for slat top
chain, Z profile to be



BFM
Flanged bronze nut,
Bronze - 1 thread

Complementary products



BEAS
Star shaped anti-
static handle, Star,
anti-static



PAS
Pull handle,
Reinforced PA
thermoplastic



BEAS
Knob star grip
antistatic, Star, anti-
static