

# Stainless steel hexagonal headed thumb nut **Sta Stock**


## EML

## Threads M5-M12

- One piece construction
- Material: stainless steel 304
- Finish: polished

### Advantages

- Does not retain dirt or dust

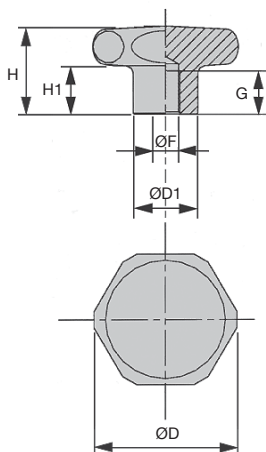

**Polished finish**

### DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List		-5%	-10%	On request

Part number	ØF	ØD	ØD1	H	H1	G	Stock*	Price each 1 to 5
EML5-27	M5	27	15	19	10,0	10	✓	22,29 €
EML6-33	M6	33	19	23	12,0	12	✓	27,96 €
EML8-40	M8	40	21	27	15,0	13	✓	34,89 €
EML10-50	M10	50	25	33	17,5	17	✓	45,85 €
EML12-60	M12	60	27	37	20,0	20	✓	59,86 €

\*Depending on availability - Dimensions in mm

## Our other products



CHTRB

Single and dual output gearboxes, Up to 53,1 Nm




RTK

BoWex® curved tooth gear coupling, Nylon and steel



SH1

 Parallel axis helical gear, Steel 20NCD2



PF15

Worm and wheel gear reducer, up to 3,75 Nm



BAG-MI

Split shaft collar with clamp lever, Steel




BUT

Panel stop, Panel stop



DOG258

 Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



T5courroie

T type timing belt, T5 Steel cored polyurethane



E20

Right angle helical reducers, from 0.60 to 5.00 Nm



G0

Steel spur gear, Steel 20NCD2



GP

Spring loaded toggle latch, Standard



PW\_PWG2

Worm - precision range, Stainless steel

## Complementary products



VML

Stainless steel hexagonal headed thumb screw, Male