

Stainless steel hexagonal headed thumb nut **Sta Stock**


EML

Threads M5-M12

- One piece construction
- Material: stainless steel 304
- Finish: polished

Advantages

- Does not retain dirt or dust

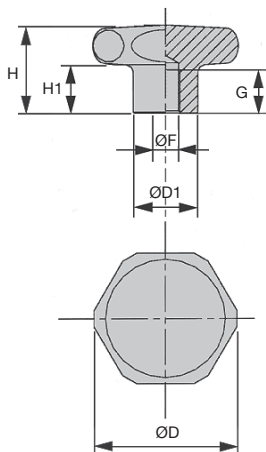

Polished finish

DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List		-5%	-10%	On request

Part number	ØF	ØD	ØD1	H	H1	G	Stock*	Price each 1 to 5
EML5-27	M5	27	15	19	10,0	10	✓	22,29 €
EML6-33	M6	33	19	23	12,0	12	✓	27,96 €
EML8-40	M8	40	21	27	15,0	13	✓	34,89 €
EML10-50	M10	50	25	33	17,5	17	✓	45,85 €
EML12-60	M12	60	27	37	20,0	20	✓	59,86 €

 
*Depending on availability - Dimensions in mm

Our other products



MLY_SS

Stainless steel bow shackle with eye bolt, Stainless steel



IN1

Internal gear, Machined plastic (delrin)



YG4

HEAVY DUTY spur gear, Steel 35NCD6



RTE

Rotex®, jaw coupling, cast iron



CHINV

Invisible hinge, Invisible - 90° opening



PCP

Cell carrier assembly, Ready assembled



T5-16ECO

T type timing pulley, Economy range - T5 aluminium



PRF-SCREEN-4

Screen support, Support with 4 axes of rotation



FUSS

Bearing locknut, Self locking locknut -



ACLBMC

Detector support for aluminium profile,



MDB_MTB

Moulded plastic bevel gear (nylon), 3:1



IN2

Internal gear, Steel 20NCD2

Complementary products



VML

Stainless steel hexagonal headed thumb screw, Male