

Stainless steel hexagonal headed thumb nut **Sta Stock**


EML

Threads M5-M12

- One piece construction
- Material: stainless steel 304
- Finish: polished

Advantages

- Does not retain dirt or dust

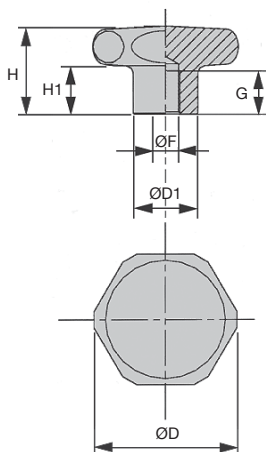

Polished finish

DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List		-5%	-10%	On request

Part number	ØF	ØD	ØD1	H	H1	G	Stock*	Price each 1 to 5
EML5-27	M5	27	15	19	10,0	10	✓	22,29 €
EML6-33	M6	33	19	23	12,0	12	✓	27,96 €
EML8-40	M8	40	21	27	15,0	13	✓	34,89 €
EML10-50	M10	50	25	33	17,5	17	✓	45,85 €
EML12-60	M12	60	27	37	20,0	20	✓	59,86 €

*Depending on availability - Dimensions in mm

Our other products



M0

Worm and wheel set,
Non hardened steel



GE1006

Elastic ringed latch,
Hooks into a slot



ACL

Joints for aluminium
profile, Variable angle
hinge



SUPCC

Self-centering
clamping hub steel,
With lock nut



NCT

Square tube
connector, Fixed
angle



TBD

Manual leadscrew
table with opposing
threads, 20kg



SLB

Indexing plunger,
steel class 5.8



MFBS

Stainless steel flexible
bellows coupling,
Stainless steel - with
cl...



CHINV

Invisible hinge,
Invisible - Opening up



M1

Worm and wheel set,
Machined plastic



BABreglable

Adjustable ball pin
hardened stainless



PM4

Worm and wheel set,
Hardened steel

Complementary products



VML

Stainless steel
hexagonal headed
thumb screw, Male