

Stainless steel hexagonal headed thumb nut **Sta Stock**


EML

Threads M5-M12

- One piece construction
- Material: stainless steel 304
- Finish: polished

Advantages

- Does not retain dirt or dust

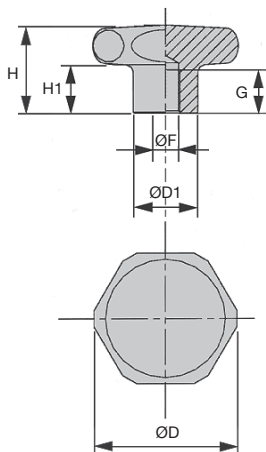

Polished finish

DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List		-5%	-10%	On request

Part number	ØF	ØD	ØD1	H	H1	G	Stock*	Price each 1 to 5
EML5-27	M5	27	15	19	10,0	10	✓	22,29 €
EML6-33	M6	33	19	23	12,0	12	✓	27,96 €
EML8-40	M8	40	21	27	15,0	13	✓	34,89 €
EML10-50	M10	50	25	33	17,5	17	✓	45,85 €
EML12-60	M12	60	27	37	20,0	20	✓	59,86 €

*Depending on availability - Dimensions in mm

Our other products



BTE

Universal tension arm,
For normal applications



RPCpl

Swivel castor with
double brake, Steel -
Polyamide



PGNT

Thermoplastic T
handle, With threaded
insert



NSA

Adjustable clamp,
Articulated



BHEX

Hexagonal cap, Black
technopolymer



AT5M AT10M

AT type timing belt
per metre, AT5 Steel
cored polyurethane



NT62

Spur gear coaxial
gearbox, from 6 to 18
Nm - In-line



BPL

Ball transfer unit light
duty, Light



VTHbr

Hexagonal headed
screw VTH - DIN933,
Brass



SH1

Parallel axis helical
gear, Machined plastic
(delrin)



PRF JL5

Lip seal for panel,
Door seal - Ø 5mm



HCV

V-rail guidance
Simple Select®
system, on rail

Complementary products



VML

Stainless steel
hexagonal headed
thumb screw, Male