



- For use in applications that do not require very tight fastening
- Material: hardened steel
- Finish: hardened and blackened

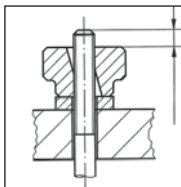


Threaded rod should be longer than dimension "H"

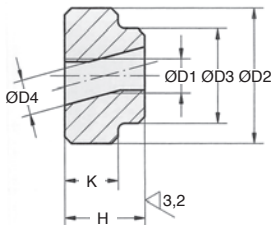

1) Tilt, and slide down.



2) Level and tighten or loosen.

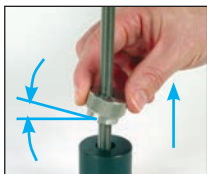

3) Tilt, and slide back up.

DISCOUNTS

Qty	1+	6+	20+	40+	60+	101+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	ØD3	ØD4	H	K	Weight (g)	Stock*	Price each 1 to 5
								✓	
EMR-5	M5	20	14	5,2	12	8	25	✓	7,63 €
EMR-6	M6	24	16	6,2	14	10	38	✓	8,86 €
EMR-8	M8	30	20	8,2	17	12	75	✓	11,46 €
EMR-10	M10	36	28	10,3	20	14	130	✓	12,59 €
EMR-12	M12	40	32	12,3	24	16	185	✓	15,80 €

*Depending on availability - Dimensions in mm

Our other products



MHXred

Reducing sleeve
male/female,
Hexagonal - steel



DOG319

Motor-gearbox 12V
and 24V DC, from 4 to
9 Nm



CHTRP

Single and dual
output gearboxes, Up
to 9,1 Nm



 
SHTP

Drylin® Linear table,
Economy range



ETQ

Magnetic label holder
for aluminium profile,
Label holder



PO

Pull handle - Multi-
sector, Smooth hole



HTD5M-BAR

HTD type tooth bar
stock, HTD5



NCT_AT

Variable angle
connector, Variable
angle



DOG319

Motor-gearbox 12V
and 24V DC, from 4 to
9 Nm



GTCSS

Belt tensioner, For use
in hostile



RNAS T

Cam follower without
axial guide, Without



PLN

Cylindrical spacer,
Thermoplastic

Complementary products



EMS

Stainless steel knurled
thumb nut, Knurled