



- For use in applications that do not require very tight fastening
- Material: hardened steel
- Finish: hardened and blackened

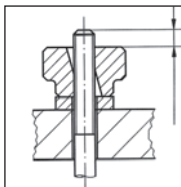


Threaded rod should be longer than dimension "H"

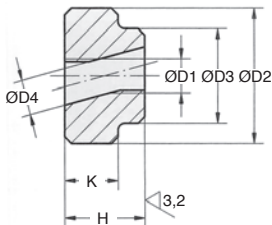

1) Tilt, and slide down.



2) Level and tighten or loosen.

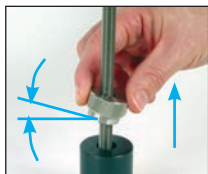

3) Tilt, and slide back up.

DISCOUNTS

Qty	1+	6+	20+	40+	60+	101+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	ØD3	ØD4	H	K	Weight (g)	Stock*	Price each 1 to 5
								✓	
EMR-5	M5	20	14	5,2	12	8	25	✓	7,63 €
EMR-6	M6	24	16	6,2	14	10	38	✓	8,86 €
EMR-8	M8	30	20	8,2	17	12	75	✓	11,46 €
EMR-10	M10	36	28	10,3	20	14	130	✓	12,59 €
EMR-12	M12	40	32	12,3	24	16	185	✓	15,80 €

*Depending on availability - Dimensions in mm

Our other products



ZBconique

Machined plastic
bevel gear , 1:1



M1

Worm and wheel set,
Hardened steel



 
PW_PWG3

Worm - precision
range, Stainless steel



BPHFclip

Clip for ball transfer
unit, Insert clip -
Installing from above



M0

Worm and wheel set,
Machined plastic
(delrin)



SSDB

Stainless steel bevel
gear, 2:1



PSG15

Spur gear - precision
range, Case hardened
steel 20NCD2



 
CHALss

Piano hinge, Stainless
steel



RJA00_28

Sealing strip, Clipping



TR

Spur round rack,
Stainless steel -



PF30NM

Worm and wheel gear
reducer, up to 8.8 Nm



FB_ECO

Eco. range steel bevel
gear, 4:1

Complementary products



EMS

Stainless steel knurled
thumb nut, Knurled