



- For use in applications that do not require very tight fastening
- Material: hardened steel
- Finish: hardened and blackened

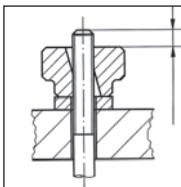


Threaded rod should be longer than dimension "H"

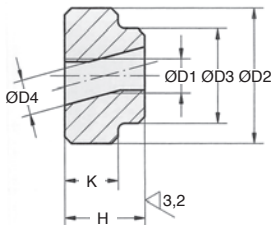

1) Tilt, and slide down.



2) Level and tighten or loosen.

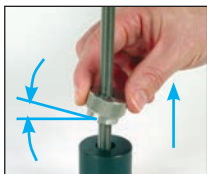

3) Tilt, and slide back up.

### DISCOUNTS

Qty	1+	6+	20+	40+	60+	101+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	ØD3	ØD4	H	K	Weight (g)	Stock*	Price each 1 to 5
								✓	
EMR-5	M5	20	14	5,2	12	8	25	✓	7,63 €
EMR-6	M6	24	16	6,2	14	10	38	✓	8,86 €
EMR-8	M8	30	20	8,2	17	12	75	✓	11,46 €
EMR-10	M10	36	28	10,3	20	14	130	✓	12,59 €
EMR-12	M12	40	32	12,3	24	16	185	✓	15,80 €

\*Depending on availability - Dimensions in mm

## Our other products



BKGS

Backlash free coupling Gerwah®, from 1.2 to 450Nm



TB8

Cylindrical roller thrust bearing, Steel



PW\_PWG2

Worm - precision range, Steel




BIM

Indexing plunger mini, miniature



AC156-157

 Strike for toggle latch, 25.5mm



TC1rp

Automatic chain tensioner, With 180° guide



BABpss

301 Stainless steel ball pin, Stainless steel



SSE

Stainless steel spherical bearing, Stainless steel / PTFE



PGNT

Thermoplastic T handle, With threaded



MC

Self-compensating shock-absorber, Self-



LRR

Spring loaded latch, Spring loaded latch



F7-E

Multifunction display, With external sensor

## Complementary products



EMS

Stainless steel knurled thumb nut, Knurled