


Threads M3-M12

EMSH
EMS_B

- Solid knurled nut
- Material: stainless steel 18.9
- Conforms to DIN 466

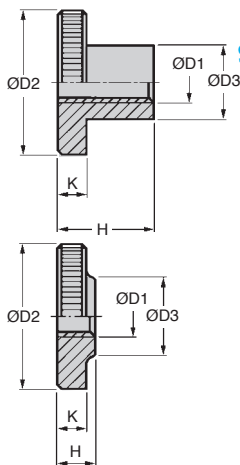

Tall version EMS-H



Low version EMS-B

DISCOUNTS

Qty	1+	6+	20+	40+	60+	101+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	ØD3	H	K	Stock*	Price each 1 to 5
High version							
EMS-3H	M3	12	6	7,5	2,5	✓	1,08 €
EMS-4H	M4	16	8	9,5	3,5	✓	1,64 €
EMS-5H	M5	20	10	11,5	4,0	✓	1,91 €
EMS-6H	M6	24	12	15,0	5,0	✓	2,99 €
EMS-8H	M8	30	16	18,0	6,0	✓	6,56 €
EMS-10H	M10	36	20	23,0	8,0	✓	10,67 €
EMS-12H	M12	36	20	23,0	8,0	✓	18,05 €
Low version							
EMS-4B	M4	16	8	4,0	3,5	✓	1,26 €
EMS-5B	M5	20	10	5,0	4,0	✓	1,68 €
EMS-6B	M6	24	12	6,0	5,0	✓	2,65 €
EMS-8B	M8	30	16	8,0	6,0	✓	6,44 €
EMS-10B	M10	36	20	10,0	8,0	✓	11,59 €
EMS-12B	M12	36	20	10,0	8,0	✓	15,25 €

*Depending on availability - Dimensions in mm

Our other products



DOMI30

Domino 30 adjustable slide, Slide DOMILINE 30 with counter and handw...



SCA_SS

Stainless steel flat cable clamp, Stainless steel



V3RA_PT

3-spoked handwheel with handle, Polyamide



DGSA

Male rod ends , Steel / steel - Economy range



G1

Steel spur gear, Steel 20NC2



BLHB30

Right angled gearbox, bored shafts, up to 4.47 Nm



BPHF

Ball transfer unit push fit, Heavy



PLM-16A

Magnetic stud with threaded hole, With threaded hole



ZDB

Machined plastic bevel gear , 2:1



MRAeco

Low cost quick link, Steel



DER80

Stainless steel AC asynchronous motor 0.55 - 0.75kW, 0.55 to 0.75kW



MFB

Flexible bellows coupling, Aluminium and Bronze - With set screw

Complementary products



VMS

Stainless steel knurled thumb screw, Knurled



EMR

Fast-locking knurled nut, Knurled