


Threads M3-M12

EMSH
EMS_B

- Solid knurled nut
- Material: stainless steel 18.9
- Conforms to DIN 466

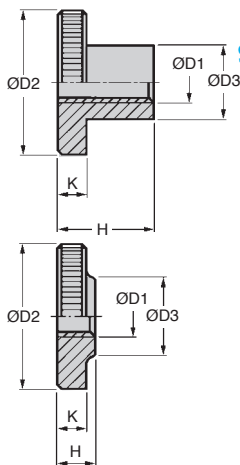

Tall version EMS-H



Low version EMS-B


DISCOUNTS

| | | | | | | |
|-------|------|------|------|------|------|------------|
| Qty | 1+ | 6+ | 20+ | 40+ | 60+ | 101+ |
| Disc. | List | -10% | -15% | -20% | -25% | On request |

| Part number | ØD1 | ØD2 | ØD3 | H | K | Stock* | Price each 1 to 5 |
|---------------------|-----|-----|-----|------|-----|--------|-------------------|
| High version | | | | | | | |
| EMS-3H | M3 | 12 | 6 | 7,5 | 2,5 | ✓ | 1,08 € |
| EMS-4H | M4 | 16 | 8 | 9,5 | 3,5 | ✓ | 1,64 € |
| EMS-5H | M5 | 20 | 10 | 11,5 | 4,0 | ✓ | 1,91 € |
| EMS-6H | M6 | 24 | 12 | 15,0 | 5,0 | ✓ | 2,99 € |
| EMS-8H | M8 | 30 | 16 | 18,0 | 6,0 | ✓ | 6,56 € |
| EMS-10H | M10 | 36 | 20 | 23,0 | 8,0 | ✓ | 10,67 € |
| EMS-12H | M12 | 36 | 20 | 23,0 | 8,0 | ✓ | 18,05 € |
| Low version | | | | | | | |
| EMS-4B | M4 | 16 | 8 | 4,0 | 3,5 | ✓ | 1,26 € |
| EMS-5B | M5 | 20 | 10 | 5,0 | 4,0 | ✓ | 1,68 € |
| EMS-6B | M6 | 24 | 12 | 6,0 | 5,0 | ✓ | 2,65 € |
| EMS-8B | M8 | 30 | 16 | 8,0 | 6,0 | ✓ | 6,44 € |
| EMS-10B | M10 | 36 | 20 | 10,0 | 8,0 | ✓ | 11,59 € |
| EMS-12B | M12 | 36 | 20 | 10,0 | 8,0 | ✓ | 15,25 € |

*Depending on availability - Dimensions in mm

Our other products

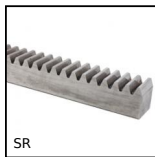


SR
Narrow spur rack,
Stainless steel



BLM
Spring loaded plunger
with ball tip, Plastic
body



RBNTc
Swivel castor with
central hole, Steel -
rubber - with double
brake

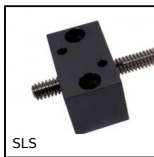

SLS
Bearing block for
leadscrew, Fixed
Drylin® bearing block



CMAss
Eye bolt stainless
steel, Stainless steel



LVT
Miniature motorised
actuator 1A, 1 amper



BPHF
Ball transfer unit push
fit, Heavy



FF30
Offset spur gear
reducer, from 21.50
to 83 Nm



GB-RA
Brass spur gear, Brass
CuZn39Pb3



BZY
Cylindrical elasto
mount, Steel



SCH
Horizontal hook
toggle clamp,
Horizontal Hook
clamp - stainless steel



ACL-FPA
Panel mounting block
for aluminium
structures, Support
block

Complementary products



VMS
Stainless steel knurled
thumb screw, Knurled



EMR
Fast-locking knurled
nut, Knurled