


Threads M3-M12

EMSH
EMS_B

- Solid knurled nut
- Material: stainless steel 18.9
- Conforms to DIN 466

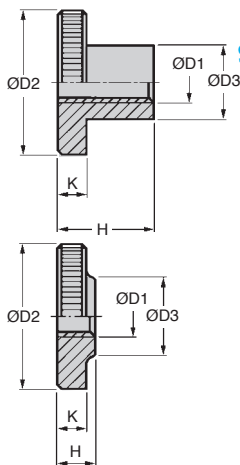

Tall version EMS-H



Low version EMS-B

DISCOUNTS

Qty	1+	6+	20+	40+	60+	101+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	ØD3	H	K	Stock*	Price each 1 to 5
High version							
EMS-3H	M3	12	6	7,5	2,5	✓	1,08 €
EMS-4H	M4	16	8	9,5	3,5	✓	1,64 €
EMS-5H	M5	20	10	11,5	4,0	✓	1,91 €
EMS-6H	M6	24	12	15,0	5,0	✓	2,99 €
EMS-8H	M8	30	16	18,0	6,0	✓	6,56 €
EMS-10H	M10	36	20	23,0	8,0	✓	10,67 €
EMS-12H	M12	36	20	23,0	8,0	✓	18,05 €
Low version							
EMS-4B	M4	16	8	4,0	3,5	✓	1,26 €
EMS-5B	M5	20	10	5,0	4,0	✓	1,68 €
EMS-6B	M6	24	12	6,0	5,0	✓	2,65 €
EMS-8B	M8	30	16	8,0	6,0	✓	6,44 €
EMS-10B	M10	36	20	10,0	8,0	✓	11,59 €
EMS-12B	M12	36	20	10,0	8,0	✓	15,25 €

*Depending on availability - Dimensions in mm

Our other products



BAG
Steel Clamping collar,
Steel



SME
Male rod ends ,
Stainless steel / PTFE



STL
Guidance brush - Rail,
Rail



TS01_TW01
Drylin® T linear slide,
up to 7000 N



 
VLBG
Lifting ring, Rotating



H0
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



ZDB
Machined plastic
bevel gear , 2:1



H1
Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



GP
Spring loaded toggle
latch, With padlock-
holder



PNA_R
PERIFLEX elastic
coupling,
Replacement tyre



VB
Small 6 lobe threaded
handle - female,
Duroplast - Brass



AT10courroie
AT type timing belt,
AT10 Steel cored
polyurethane

Complementary products