


Threads M3-M12

EMSH  
EMS<sub>B</sub>

- Solid knurled nut
- Material: stainless steel 18.9
- Conforms to DIN 466

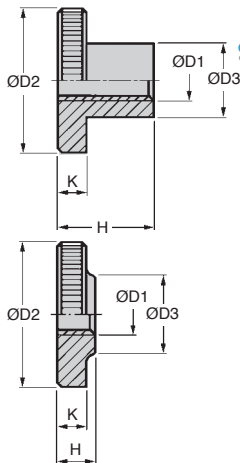

Tall version EMS-H



Low version EMS-B

## DISCOUNTS

Qty	1+	6+	20+	40+	60+	101+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	ØD3	H	K	Stock*	Price each 1 to 5
<b>High version</b>							
EMS-3H	M3	12	6	7,5	2,5	✓	1,08 €
EMS-4H	M4	16	8	9,5	3,5	✓	1,64 €
EMS-5H	M5	20	10	11,5	4,0	✓	1,91 €
EMS-6H	M6	24	12	15,0	5,0	✓	2,99 €
EMS-8H	M8	30	16	18,0	6,0	✓	6,56 €
EMS-10H	M10	36	20	23,0	8,0	✓	10,67 €
EMS-12H	M12	36	20	23,0	8,0	✓	18,05 €
<b>Low version</b>							
EMS-4B	M4	16	8	4,0	3,5	✓	1,26 €
EMS-5B	M5	20	10	5,0	4,0	✓	1,68 €
EMS-6B	M6	24	12	6,0	5,0	✓	2,65 €
EMS-8B	M8	30	16	8,0	6,0	✓	6,44 €
EMS-10B	M10	36	20	10,0	8,0	✓	11,59 €
EMS-12B	M12	36	20	10,0	8,0	✓	15,25 €

\*Depending on availability - Dimensions in mm

## Our other products



KKP-AR

Linear bearing with inclined ball tracks, Heavy loads / -20° +200°



PRF\_CLIP\_22

Cable clip for aluminium profile, For electric and pneumatic cables



SLB

Indexing plunger, steel class 5.8



DOMI120

Connecting kits, XZ linking kit



PW\_PWG1

Worm - precision range, Steel




F7-I

Multifunction display, With internal sensor



AT5M AT10M

AT type timing belt per metre, AT10 Steel cored polyurethane

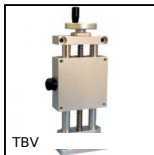

TBV

Manual lifting tables, 20kg



ATZY

Diabolo shaped elastomount, Steel



BDPR

Holding arm, Rigid



CHAupa

Front hinge, 270°



DOMI50

Accessories, Turntable

## Complementary products



VMS

Stainless steel knurled thumb screw, Knurled



EMR

Fast-locking knurled nut, Knurled