

Narrow wing nuts




EPEHDSS

Hygienic Design®

- **Narrow wing nut, manual operation**
- Allows a threaded connection to be made very easily
- Tool-free handling
- Fully polished surface
- Material:
Stainless steel 1.4404 (316L)
Polished finish <math>< Ra 0.8 \mu m</math>

Advantages

- Polished surface allows for easy cleaning
- Dirt or residue from products or cleaners will not adhere.

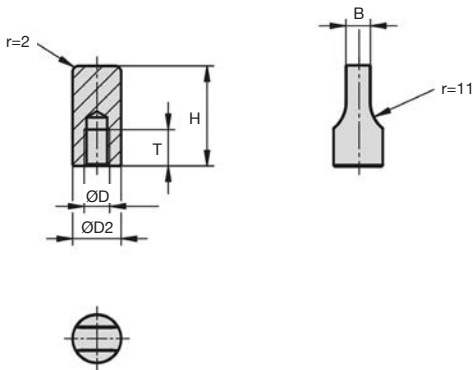

DISCOUNTS

| | | | | |
|------|-----|-----|------|------------|
| Qty | 1+ | 5+ | 10+ | 25+ |
| Disc | Net | -5% | -10% | On request |

| Part N° | ØD | ØD2 | H | B | T | Price each |
|-------------|-----|-----|----|------|----|------------|
| | | | | | | 1 to 4 |
| EPE-4/HDSS | M4 | 9 | 20 | 4,5 | 6 | 11,69 € |
| EPE-5/HDSS | M5 | 10 | 22 | 4,5 | 6 | 12,12 € |
| EPE-6/HDSS | M6 | 12 | 22 | 5,5 | 7 | 13,20 € |
| EPE-8/HDSS | M8 | 16 | 25 | 8,0 | 9 | 13,62 € |
| EPE-10/HDSS | M10 | 20 | 30 | 10,0 | 11 | 14,52 € |

All dimensions in mm

Our other products



Q6

Deep groove ball bearing, Steel



G2

Steel spur gear, Steel 20NCD2



MDR

Dee shackle with eye bolt, Steel



LVT

Miniature motorised actuator 1A, 1 ampere



MEB

Moulded plastic bevel gear (nylon), 1:1



TBD

Manual leadscrew table with opposing threads, 2kg



GP75

Spring loaded toggle latch, Standard (GP75)



NCT

Square tube connector, Fixed angle



PLA

Flat magnet, Flat magnet with thread



ZDB

Machined plastic bevel gear, 2:1



BLHT70

Right angled gearbox, from 26 to 128 Nm



RPCTcss

Swivel castor with central hole, Stainless steel - Polyamide - with ...

Complementary products