

# Narrow wing nuts




EPEHDSS

Hygienic Design®

- **Narrow wing nut, manual operation**
- Allows a threaded connection to be made very easily
- Tool-free handling
- Fully polished surface
- Material:  
Stainless steel 1.4404 (316L)  
Polished finish <math>< Ra 0.8 \mu m</math>

## Advantages

- Polished surface allows for easy cleaning
- Dirt or residue from products or cleaners will not adhere.

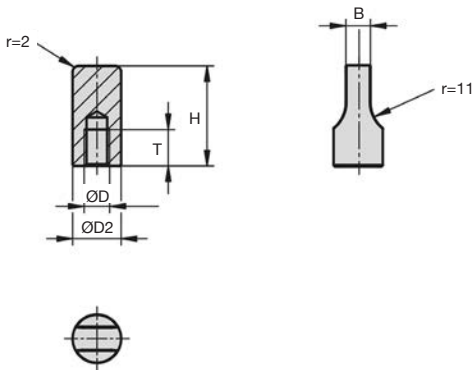

## DISCOUNTS

Qty	1+	5+	10+	25+
Disc	Net	-5%	-10%	On request

Part N°	ØD	ØD2	H	B	T	Price each
						1 to 4
EPE-4/HDSS	M4	9	20	4,5	6	11,69 €
EPE-5/HDSS	M5	10	22	4,5	6	12,12 €
EPE-6/HDSS	M6	12	22	5,5	7	13,20 €
EPE-8/HDSS	M8	16	25	8,0	9	13,62 €
EPE-10/HDSS	M10	20	30	10,0	11	14,52 €

All dimensions in mm

## Our other products



STRIP

Sealing brush strip,  
3m length



TBL

Mini leadscrew table  
with metric thread,  
1kg



GG2

Ground spur gear,  
Heat treated steel



AC156-157

Strike for toggle latch,  
25.5mm



T5P\_T10P

Connecting plate for T  
type timing belts, T10



CHML50

Worm and wheel gear  
reducer, up to 107  
Nm - Integrated  
torque limiter



 
AT5P\_AT10P

Connecting plate for  
AT type timing belts,  
AT10



BPPL

Assembly tool for  
carrier ball, Mounting  
tool



ACLBTS

Closing system for  
aluminium profile, 90°



PSG055

Spur gear - precision  
range, Stainless steel



RHTplss

High Temperature  
Castor, up to 200kg



CLB\_M

Die cast zinc clamping  
lever - female, Zamak

## Complementary products