

# Narrow wing nuts




EPEHDSS

Hygienic Design®

- **Narrow wing nut, manual operation**
- Allows a threaded connection to be made very easily
- Tool-free handling
- Fully polished surface
- Material:  
Stainless steel 1.4404 (316L)  
Polished finish < Ra 0.8 µm

## Advantages

- Polished surface allows for easy cleaning
- Dirt or residue from products or cleaners will not adhere.

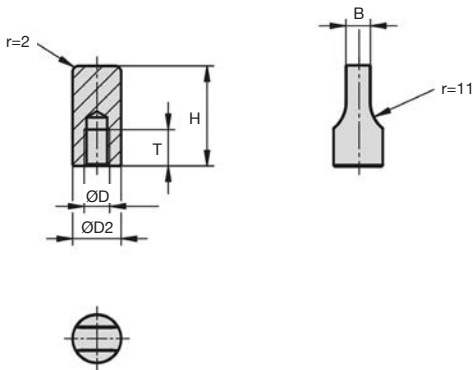

## DISCOUNTS

|      |     |     |      |            |
|------|-----|-----|------|------------|
| Qty  | 1+  | 5+  | 10+  | 25+        |
| Disc | Net | -5% | -10% | On request |

| Part N°     | ØD  | ØD2 | H  | B    | T  | Price each |
|-------------|-----|-----|----|------|----|------------|
|             |     |     |    |      |    | 1 to 4     |
| EPE-4/HDSS  | M4  | 9   | 20 | 4,5  | 6  | 11,69 €    |
| EPE-5/HDSS  | M5  | 10  | 22 | 4,5  | 6  | 12,12 €    |
| EPE-6/HDSS  | M6  | 12  | 22 | 5,5  | 7  | 13,20 €    |
| EPE-8/HDSS  | M8  | 16  | 25 | 8,0  | 9  | 13,62 €    |
| EPE-10/HDSS | M10 | 20  | 30 | 10,0 | 11 | 14,52 €    |

All dimensions in mm

## Our other products



GE32  
Sprung toggle latch  
with connecting link,  
Standard



VMS  
Stainless steel knurled  
thumb screw, Knurled



DOMI50  
Accessories, Fixing kit



PGNT  
Thermoplastic T  
handle, With threaded  
insert



BIMSS  
Indexing plunger mini,  
miniature - Stainless  
steel



CLSCLP\_SS  
Clevis components,  
short version,  
Stainless steel - short  
range



MAX26  
Motor-gearbox 12V  
and 24V DC, from  
0,075 to 0,6Nm



BPM\_LOK  
Long-Lok slotted  
spring plunger with  
ball tip, LONG-LOK -  
Steel



SUA4\_L  
Chain link, Steel



AC156-157  
Strike for toggle latch,  
25.5mm



GE\_ES  
Spherical bushing,  
Steel / steel



EHD12  
Internal epicyclic  
servo reducers, from  
60 to 140 Nm

## Complementary products