

Narrow wing nuts




EPEHDSS

Hygienic Design®

- **Narrow wing nut, manual operation**
- Allows a threaded connection to be made very easily
- Tool-free handling
- Fully polished surface
- Material:
Stainless steel 1.4404 (316L)
Polished finish <math>< Ra 0.8 \mu m</math>

Advantages

- Polished surface allows for easy cleaning
- Dirt or residue from products or cleaners will not adhere.

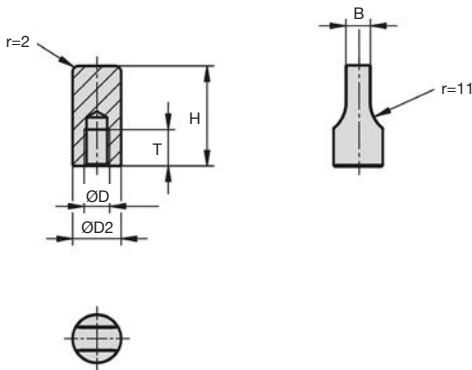

DISCOUNTS

Qty	1+	5+	10+	25+
Disc	Net	-5%	-10%	On request


Part N°	ØD	ØD2	H	B	T	Price each
						1 to 4
EPE-4/HDSS	M4	9	20	4,5	6	11,69 €
EPE-5/HDSS	M5	10	22	4,5	6	12,12 €
EPE-6/HDSS	M6	12	22	5,5	7	13,20 €
EPE-8/HDSS	M8	16	25	8,0	9	13,62 €
EPE-10/HDSS	M10	20	30	10,0	11	14,52 €

All dimensions in mm

Our other products



 SLV
Vertical toggle clamp,
Vertical Lever Clamp -
steel



EPRF
High helix leadscrew,
Flanged nut - up to
40mm per rotation



BSP
Compact precision
slide, from 156 N to
980 N



PITAss
Locking bolt, with T
handle




PFC
Fixed rubber levelling
foot, Levelling support
for small parts



GSI_A
Stainless steel
adjustable gas spring,
Stainless steel



SHA_PTR
Handwheel with
folding handle,
Polyamide

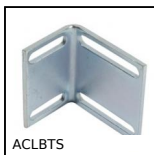

ACLBS
Closing system for
aluminium profile, 90°
bracket for spherical
end...



GLB
Small 6 lobe threaded
handle - female,
Technopolymer -



BABpss
301 Stainless steel
ball pin, Stainless
steel



MET
Cylindrical sintered
bronze bush, Self-
lubricating sintered



MAX26
Motor-gearbox 12V
and 24V DC, from
0,075 to 0,6Nm

Complementary products