

# Narrow wing nuts




EPEHDSS

Hygienic Design®

- **Narrow wing nut, manual operation**
- Allows a threaded connection to be made very easily
- Tool-free handling
- Fully polished surface
- Material:  
Stainless steel 1.4404 (316L)  
Polished finish <math>< Ra 0.8 \mu m</math>

## Advantages

- Polished surface allows for easy cleaning
- Dirt or residue from products or cleaners will not adhere.

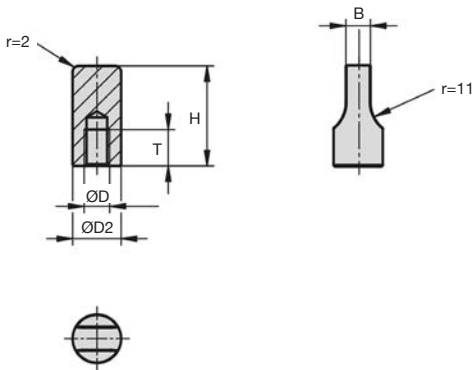

## DISCOUNTS

Qty	1+	5+	10+	25+
Disc	Net	-5%	-10%	On request

Part N°	ØD	ØD2	H	B	T	Price each
						1 to 4
EPE-4/HDSS	M4	9	20	4,5	6	11,69 €
EPE-5/HDSS	M5	10	22	4,5	6	12,12 €
EPE-6/HDSS	M6	12	22	5,5	7	13,20 €
EPE-8/HDSS	M8	16	25	8,0	9	13,62 €
EPE-10/HDSS	M10	20	30	10,0	11	14,52 €

All dimensions in mm

## Our other products



DOMI120

DOMILINE -  
Adjustment slide,  
Slide DOMILINE 120  
with counter and



RPC

Wheel, Polyamide



WSS

Symmetrical S shaped  
hook, Steel



CAP880

Flexible plate chain,  
Narrow range 880



PTGP

Tensioner pulley, For  
flat belts



PRF\_PIV

Hinges and joints,  
Internal hinge pin



gt64



EHD06

Epicyclic servo  
gearbox, from 8 to 19  
Nm



CSSSS

Spherical bearing,  
Stainless steel / PTFE



DGSI

Rod end, Steel / steel  
- Economy range



CLQ

Bearing - accessories,  
Feeler strip on rolls



DFG

Suction cup, silicon

## Complementary products



EPL

Wing nuts Hygienic  
Design®, Wide