 

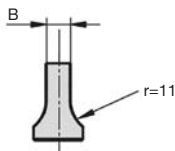


- **Wide wing nut, manual operation**
- Allows a threaded connection to be made very easily
- Tool-free handling
- Fully polished surface
- Material:
Stainless steel 1.4404 (316L)
Polished finish < Ra 0.8 µm

Advantages

- Good grip
- Polished surface allows for easy cleaning, dirt or residue from products or cleaners will not adhere.

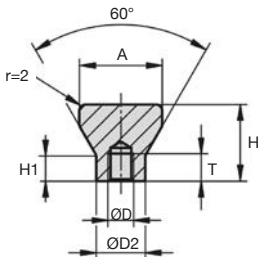

DISCOUNTS

Qty	1+	5+	10+	25+
Disc	Net	-5%	-10%	On request

Part N°	ØD	ØD2	A	B	H	H1	T	Price each 1 to 4
EPL-4/HDSS	M4	9	20	4,5	20	5,0	6	15,21 €
EPL-5/HDSS	M5	10	22	4,5	22	5,9	6	15,76 €
EPL-6/HDSS	M6	12	25	5,5	22	5,0	7	16,30 €
EPL-8/HDSS	M8	16	27	8,0	25	8,5	9	17,01 €
EPL-10/HDSS	M10	20	30	10,0	30	10,0	11	18,99 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Our other products



CHML50
Worm and wheel
gearbox, up to 107
Nm - Integrated
torque limiter



DFG
Suction cup, silicon



AT5M AT10M
Timing belt per metre,
AT10 Steel cored
polyurethane



ACM_TRI
Manual bonnet
fastener, Black rubber
fastener




PRF1945
Standard aluminium
profile, 19 x 45 mm



VPSS
Small 6 lobe threaded
handle, Duroplast -
Stainless steel



CHAL3
Piano hinge, Steel

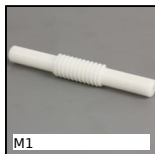

M1
Worm, Machined
plastic (delrin)



DOMI50
DOMILINE -
Accessories, Turntable



SK
Knob for clamping,
Star, rounded



DOMI80
DOMILINE -
Adjustment slide,
Slide DOMILINE 80



RJA11_27
Linear sealing strip,
Not clipping

Complementary products



EPE
Wing nuts Hygienic
Design®, Narrow