

Cylindrical nut for high helix lead-screw

EPRC

Up to 40mm
of travel per rotation


- Nut only
- Right handed thread
- Lubricant free, low wear
- Material:
Iglidur J

Accessories

- Used with TPR high helix lead-screws
(not compatible with LPR lead-screws)

Advantages

- High efficiency irrespective of speed
- Low wear
- Excellent coefficient of friction
- High speed

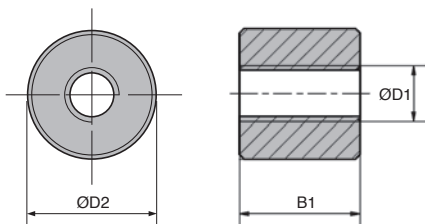

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØD1	Pitch P (mm)	ØD2	B1	Max axial static force (N)	Stock*	Price each 1 to 4
EPRC6.35-2.54	6,35	2,54	14	13	1000	-	27,86 €
EPRC6.35-25.4	6,35	25,4	14	13	75	✓	42,17 €
EPRC10-12	10	12	22	20	677	4	40,89 €
EPRC10-25	10	25	22	20	780	-	32,49 €
EPRC10-50	10	50	22	20	453	-	32,49 €
EPRC14-25	14	25	30	27	1101	✓	38,57 €
EPRC14-30	14	30	30	27	1101	-	38,57 €
EPRC18-40	18	40	40	36	1966	✓	37,92 €

Dimensions in mm

Our other products



SDB

Locking bolt support bracket, Mounting holes at 90° to locating bolt



HTD5M_25

HTD Heavy duty timing pulley, HTD5 Aluminium



NT62

Spur gear coaxial gearbox, from 6 to 18 Nm - In-line



SLH-M

Nut for toggle clamp, Round ended nut for SLH/SLV clamp



PR40

Articulated foot Ø40, Ø 40



RPB

Ballscrew bearing unit, Support



NSO

Housing for open linear bearing, Opened - long



VHTM

Hexagonal headed screw Hygienic Design®, Stainless steel



ACLERP

Roller block for aluminium profile, Without guide rail



SHSS

Shoulder screw stainless steel 416, Pre-treated 416



TBD

 
Manual leadscrew table with opposing threads, 5kg



TCC_SS


Stainless steel rigging screw (hook/hook), Stainless steel

Complementary products



TPR

 High helix leadscrew, Leadscrew only - up to 40mm per rotation



EPRF

High helix leadscrew, Flanged nut - up to 40mm per rotation