

Cylindrical nut for high helix lead-screw

EPRC

Up to 40mm
of travel per rotation


- Nut only
- Right handed thread
- Lubricant free, low wear
- Material:
Iglidur J

Accessories

- Used with TPR high helix lead-screws
(not compatible with LPR lead-screws)

Advantages

- High efficiency irrespective of speed
- Low wear
- Excellent coefficient of friction
- High speed

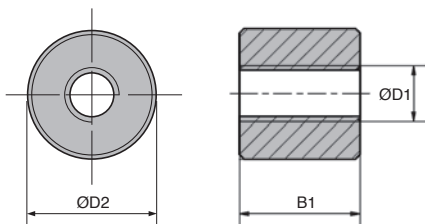

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØD1	Pitch P (mm)	ØD2	B1	Max axial static force (N)	Stock*	Price each 1 to 4
EPRC6.35-2.54	6,35	2,54	14	13	1000	-	27,86 €
EPRC6.35-25.4	6,35	25,4	14	13	75	✓	42,17 €
EPRC10-12	10	12	22	20	677	4	40,89 €
EPRC10-25	10	25	22	20	780	-	32,49 €
EPRC10-50	10	50	22	20	453	-	32,49 €
EPRC14-25	14	25	30	27	1101	✓	38,57 €
EPRC14-30	14	30	30	27	1101	-	38,57 €
EPRC18-40	18	40	40	36	1966	✓	37,92 €

Dimensions in mm


Our other products



RFK48C
Hypoid gearbox -
Stainless steel, up to
350 Nm



PTRSS
Idler chain sprocket,
For hostile
environments

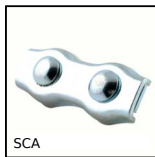

SCA
Flat cable clamp,
Steel



PR820
Idler sprocket for slat
top chain, Rangs 820
and 815



EZY
Cylindrical stop, Steel



PF30NM
Worm and wheel gear
reducer, up to 8.8 Nm



PW_PWG3
Worm - precision
range, Steel



ACLBMC
Detector support for
aluminium profile,
Sensor holder



GMK17_R
Round guide, Round
guide for conical
profile



ADL_F
Female eye bolt
conforms to DIN582,
Steel

 


UGCG
Actuator guide kit,
Long housing




UCF_PBT
Stainless
steel/Polymer flanged
bearing, Polymer and
stainless steel

Complementary products



 TPR
High helix leadscrew,
Leadscrew only - up
to 40mm per rotation



EPRF
High helix leadscrew,
Flanged nut - up to
40mm per rotation