

Cylindrical nut for high helix lead-screw

EPRC

Up to 40mm
of travel per rotation


- Nut only
- Right handed thread
- Lubricant free, low wear
- Material:
Iglidur J

Accessories

- Used with TPR high helix lead-screws
(not compatible with LPR lead-screws)

Advantages

- High efficiency irrespective of speed
- Low wear
- Excellent coefficient of friction
- High speed

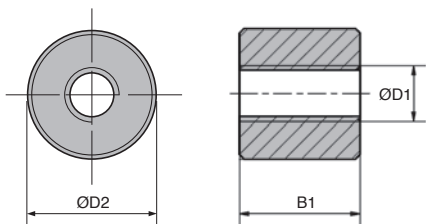

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØD1	Pitch P (mm)	ØD2	B1	Max axial static force (N)	Stock*	Price each 1 to 4
EPRC6.35-2.54	6,35	2,54	14	13	1000	-	27,86 €
EPRC6.35-25.4	6,35	25,4	14	13	75	✓	42,17 €
EPRC10-12	10	12	22	20	677	4	40,89 €
EPRC10-25	10	25	22	20	780	-	32,49 €
EPRC10-50	10	50	22	20	453	-	32,49 €
EPRC14-25	14	25	30	27	1101	✓	38,57 €
EPRC14-30	14	30	30	27	1101	-	38,57 €
EPRC18-40	18	40	40	36	1966	✓	37,92 €

Dimensions in mm

Our other products



HAS

Captive C washer,
Slotted flat headed
shoulder screw



HS

Hexagonal spacer,
Stainless steel 303



PRF-SRA

Lock for aluminium
profile, Lock



PR40

Articulated foot Ø50,
Ø 50



PSPE20

Conical flexible shaft
handle Ø20, Black
PVC



BPFL

Sheet steel flanged
bearing for light
loads, Sheet steel



BLHB50

Right angled gearbox,
bored shafts, up to 30
Nm



HW_HT

Half-rail guide, Rail



 
LVT

Miniature motorised
actuator 4A, 4 amperes




CLAT

Clamping lever
Hygienic Usit® -



AC


Strike for toggle latch,
15mm

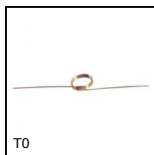

T0


Torsion spring,
Stainless steel

 Complementary products



TPR

 High helix leadscrew,
Leadscrew only - up
to 40mm per rotation



EPRF

High helix leadscrew,
Flanged nut - up to
40mm per rotation