

Flanged nut for high helix lead-screw

EPRF

Up to 40mm
of travel per rotation



- Nut only
- Right handed thread
- Lubricant free, low wear
- Material:
Iglidur J

Accessories

- Used efficiency irrespective of speed

Advantages

- High efficiency irrespective of speed
- Low wear
- Excellent coefficient of friction
- High speed

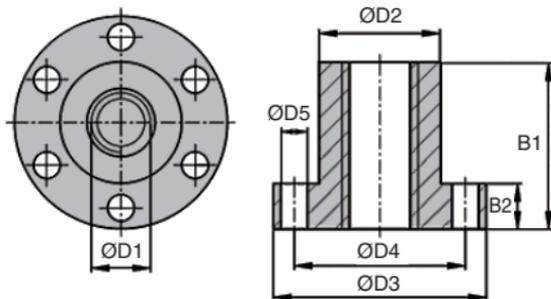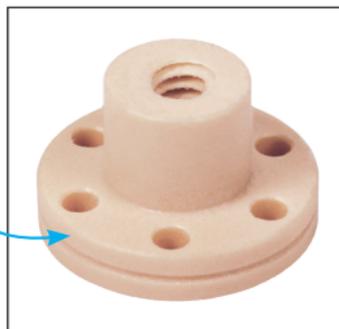

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Pitch P	ØD1 (mm)	ØD2	ØD3	ØD4	ØD5	B1	B2	Max axial static force (N)	Stock*	Price each 1 to 4
EPRF6.35-2.54	6,35	2,54	13	25	19	3,2	15	5	125	-	34,86 €
EPRF6.35-25.4	6,35	25,4	13	25	19	3,2	15	5	125	-	34,86 €
EPRF10-12	10	12	25	42	34	5	25	10	845	✓	47,08 €
EPRF10-25	10	25	25	42	34	5	25	10	780	-	43,84 €
EPRF10-50	10	50	25	42	34	5	25	10	453	-	51,89 €
EPRF14-25	14	25	28	48	38	6	35	12	1428	✓	56,89 €
EPRF14-30	14	30	28	48	38	6	35	12	1428	-	59,75 €
EPRF18-40	18	40	28	48	38	6	35	12	1910	✓	71,71 €

Dimensions in mm

Our other products



BKGS
Backlash free
coupling Gerwah®,
from 1.2 to 450Nm



BVR
Adjustable screw stop,
Steel




T10courroie
T type timing belt,
T10 Steel cored
polyurethane



M1
Worm and wheel set,
Non hardened steel




TUBE25_25
Square Tube,
Aluminium or
Stainless steel

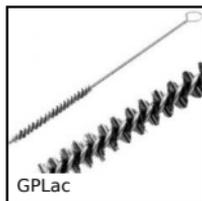

GPLac
Brush, steel



VTA
Vari-Tork® slip
friction clutch, 0.53 to
1.32 Nm

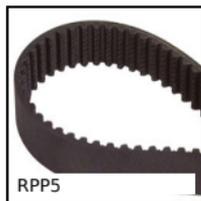

RPP5
RPP heavy duty
timing belt, RPP5



CHB
Single output shaft,
For CHB gearbox



PGMSS
Stainless steel
push/pull handle,
Stainless steel




BPTR
End cap for round
tube, Standard



BPPEBLU
Ball transfer unit in
blue certified plastic,
for foodstuff sector

Complementary products

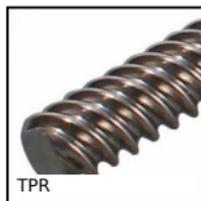

TPR
High helix leadscrew,
Leadscrew only - up
to 40mm per rotation



EPRC
High helix leadscrew,
Cylindrical nut - up to
40mm per rotation