

Flanged nut for high helix lead-screw

EPRF

Up to 40mm
of travel per rotation




- Nut only
- Right handed thread
- Lubricant free, low wear
- Material:
Iglidur J

Accessories

- Used efficiency irrespective of speed

Advantages

- High efficiency irrespective of speed
- Low wear
- Excellent coefficient of friction
- High speed

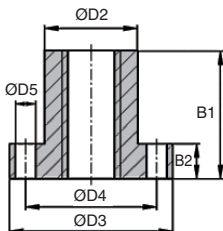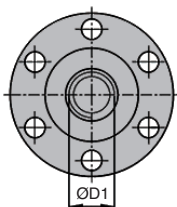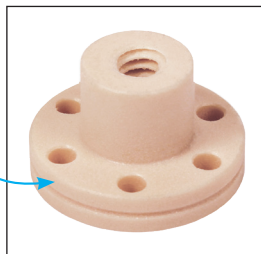

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	Pitch P	ØD1 (mm)	ØD2	ØD3	ØD4	ØD5	B1	B2	Max axial static force (N)	Stock*	Price each
											1 to 4
EPRF6.35-2.54	6,35	2,54	13	25	19	3,2	15	5	125	-	34,86 €
EPRF6.35-25.4	6,35	25,4	13	25	19	3,2	15	5	125	-	34,86 €
EPRF10-12	10	12	25	42	34	5	25	10	845	✓	47,08 €
EPRF10-25	10	25	25	42	34	5	25	10	780	-	43,84 €
EPRF10-50	10	50	25	42	34	5	25	10	453	-	51,89 €
EPRF14-25	14	25	28	48	38	6	35	12	1428	✓	56,89 €
EPRF14-30	14	30	28	48	38	6	35	12	1428	-	59,75 €
EPRF18-40	18	40	28	48	38	6	35	12	1910	✓	71,71 €

Dimensions in mm

Our other products



HTD5M_15

HTD Heavy duty timing pulley, HTD5 Aluminium



HLC19

Right angle spiro bevel gearbox, Up to 43Nm



MHX

Hexagonal threaded sleeve, Hexagonal - steel



CHM50-MOT

Asynchronous AC motorgearboxes 0.18 to 0.75kW, 0.18 to 0.75kW



E60

Right angle helical reducers, from 4.50 to 62 Nm



E50

Right angle helical reducers, from 3 to 41 Nm



RVM25

Manually operated gearbox, Bevel



SVT30

Screwjack with travelling screw, with translating screw



VLBS

Folding lifting ring for welding, Folding - for



PLM-C

Cylindrical holding magnets, Cylindrical



ASL

 
45° Hoist ring for welding, for 45° lifts -



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1

Complementary products



TPR

High helix leadscrew, Leadscrew only - up to 40mm per rotation



EPRC

High helix leadscrew, Cylindrical nut - up to 40mm per rotation