

Quick fitting cable terminals

Sta

ERCss
ERLss



Fork and eye versions

- Cable terminals for wires, manual crimping

- Material: Stainless steel 316

Advantage

- Rapid manual assembly

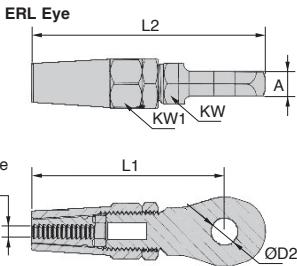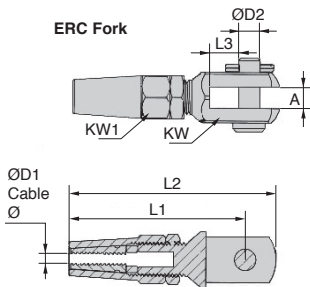

DISCOUNTS

Qty	1+	4+	10+	15+
Disc.	List	-10%	-20%	On request

Part number	ØD1	ØD2	A	L1	L2	L3	KW	KW1	Weight (g)	Stock*	Price each 1 to 3
										✓	
Fork											
ERC3-6/SS	3	6	6,25	49,0	57,0	8,0	12	14	40	✓	28,96 €
ERC4-8/SS	4	8	7,90	60,5	71,4	8,3	14	19	80	✓	34,07 €
ERC5-10/SS	5	10	9,70	69,0	79,0	10,0	16	22	120	-	40,27 €
ERC6-12/SS	6	12	11,00	81,0	93,0	12,0	19	27	210	✓	50,66 €
ERC8-14/SS	8	14	13,00	106,0	120,0	15,0	24	30	376	-	69,70 €
Eye											
ERL3-6/SS	3	6	6	48	57	-	10	12	34	✓	30,38 €
ERL4-8/SS	4	8	7	56	69	-	14	14	62	-	34,66 €
ERL5-10/SS	5	10	8	66	82	-	14	16	88	-	40,91 €
ERL6-13/SS	6	13	9	83	100	-	17	19	154	-	49,95 €
ERL8-14/SS	8	14	10	102	123	-	19	24	278	-	65,82 €

* Depending on availability - Dimensions in mm

Our other products



SSE

Stainless steel spherical bearing,
Stainless steel / PTFE



GE1006

Elastic ringed latch,
Hooks into a slot



RPP

Connecting plate for
RPP type timing belts,
RPP8



BEAB

Knob star grip
antibacterial, Star,
anti-bacterial



PM2

Worm and wheel set,
Hardened steel



RURp

Fixed castor with
plate, Polyurethane -
Aluminium rim (Free
running)



SVT30

Screwjack with
travelling screw, with
translating screw



PPF

Indexing plunger with
flange, with drilled
flange



NSR

Adjustable clamp,
Adjustable



NJM

Multiple junction
clamp, Multiple



GAL21


Conveyor wheel,
Plastic



PP50

Worm and wheel gear
reducer, from 6.50 to
12.80 Nm

 Complementary products



CAB

Stainless steel cable,
Stainless steel



ERC

Quick fitting cable
terminal, Eye version



RDERSS

Stainless steel manual
rigging screw,
Stainless steel -
manual



CABPVC

PVC covered
galvanised steel
cable, Galvanised
steel with

