

Quick fitting cable terminals

Sta

ERCss
ERLss



Fork and eye versions

- Cable terminals for wires, manual crimping

- Material: Stainless steel 316

Advantage

- Rapid manual assembly

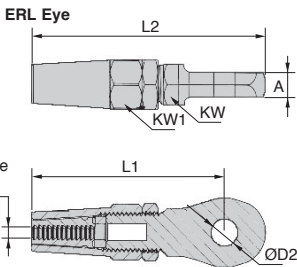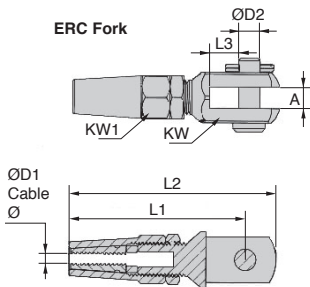

DISCOUNTS

| Qty | 1+ | 4+ | 10+ | 15+ |
|-------|------|------|------|------------|
| Disc. | List | -10% | -20% | On request |

| Part number | ØD1 | ØD2 | A | L1 | L2 | L3 | KW | KW1 | Weight (g) | Stock* | Price each 1 to 3 |
|-------------|-----|-----|-------|-------|-------|------|----|-----|------------|--------|-------------------|
| Fork | | | | | | | | | | | |
| ERC3-6/SS | 3 | 6 | 6,25 | 49,0 | 57,0 | 8,0 | 12 | 14 | 40 | ✓ | 28,96 € |
| ERC4-8/SS | 4 | 8 | 7,90 | 60,5 | 71,4 | 8,3 | 14 | 19 | 80 | ✓ | 34,07 € |
| ERC5-10/SS | 5 | 10 | 9,70 | 69,0 | 79,0 | 10,0 | 16 | 22 | 120 | - | 40,27 € |
| ERC6-12/SS | 6 | 12 | 11,00 | 81,0 | 93,0 | 12,0 | 19 | 27 | 210 | ✓ | 50,66 € |
| ERC8-14/SS | 8 | 14 | 13,00 | 106,0 | 120,0 | 15,0 | 24 | 30 | 376 | - | 69,70 € |
| Eye | | | | | | | | | | | |
| ERL3-6/SS | 3 | 6 | 6 | 48 | 57 | - | 10 | 12 | 34 | ✓ | 30,38 € |
| ERL4-8/SS | 4 | 8 | 7 | 56 | 69 | - | 14 | 14 | 62 | - | 34,66 € |
| ERL5-10/SS | 5 | 10 | 8 | 66 | 82 | - | 14 | 16 | 88 | - | 40,91 € |
| ERL6-13/SS | 6 | 13 | 9 | 83 | 100 | - | 17 | 19 | 154 | - | 49,95 € |
| ERL8-14/SS | 8 | 14 | 10 | 102 | 123 | - | 19 | 24 | 278 | - | 65,82 € |

* Depending on availability - Dimensions in mm

Our other products



CSSSS

Stainless steel spherical bearing, Stainless steel / PTFE



SERB

Cam latch, Cam latch



CLA

Clamping lever Hygienic Usit® - female, Stainless steel



DOG258

Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



ACLCHAR

Hinge for aluminium profile, With elongated holes



OPFL_OPPM

Numerical counter accessories, Locking clamp



CHTRP

Single and dual output gearboxes, Up to 75,7 Nm



SBS_L

Chain link, Stainless steel



PAMF100EB

Articulated foot with sheet metal base Ø100, Articulated foot



 
B3PAN

Panamech, Multi-Beam stainless steel, Stainless steel - with



MPS


Hexagonal spacer, Stainless steel 303



TC1rp

Automatic chain tensioner, With 180° guide

 Complementary products



CAB

Stainless steel cable, Stainless steel



ERC

Quick fitting cable terminal, Eye version



RDERSS

Stainless steel manual rigging screw, Stainless steel - manual



CABPVC

PVC covered galvanised steel cable, Galvanised steel with

