

Quick fitting cable terminals

Sta

ERCss
ERLss

Fork and eye versions

- Cable terminals for wires, manual crimping

- Material: Stainless steel 316

Advantage

- Rapid manual assembly




ERL Eye




ERC Fork

stainless steel


Manually crimped

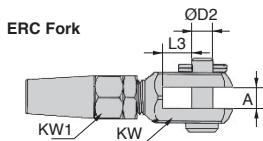


ERC Fork

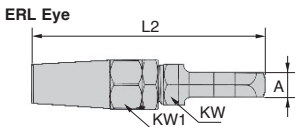

ERL Eye

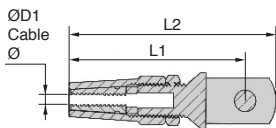

ØD1
Cable
Ø

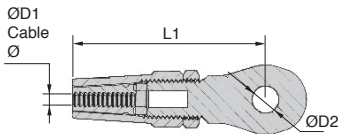

ØD1
Cable
Ø

DISCOUNTS

Qty	1+	4+	10+	15+
Disc.	List	-10%	-20%	On request

Part number	ØD1	ØD2	A	L1	L2	L3	KW	KW1	Weight (g)	Stock*	Price each 1 to 3
Fork											
ERC3-6/SS	3	6	6,25	49,0	57,0	8,0	12	14	40	✓	28,96 €
ERC4-8/SS	4	8	7,90	60,5	71,4	8,3	14	19	80	✓	34,07 €
ERC5-10/SS	5	10	9,70	69,0	79,0	10,0	16	22	120	-	40,27 €
ERC6-12/SS	6	12	11,00	81,0	93,0	12,0	19	27	210	✓	50,66 €
ERC8-14/SS	8	14	13,00	106,0	120,0	15,0	24	30	376	-	69,70 €
Eye											
ERL3-6/SS	3	6	6	48	57	-	10	12	34	✓	30,38 €
ERL4-8/SS	4	8	7	56	69	-	14	14	62	-	34,66 €
ERL5-10/SS	5	10	8	66	82	-	14	16	88	-	40,91 €
ERL6-13/SS	6	13	9	83	100	-	17	19	154	-	49,95 €
ERL8-14/SS	8	14	10	102	123	-	19	24	278	-	65,82 €

* Depending on availability - Dimensions in mm


HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel


Our other products

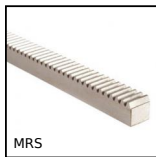

MRS
Stainless steel metric section rack, Stainless steel



VRC2
Retaining clamp, dual sided, Dual sided

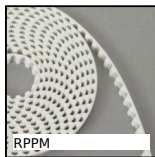

RPPM
RPP type belt per metre, RPP8 Steel cored polyurethane



RPCtc
Swivel castor with central hole, Steel - Polyamide



PM3
Worm and wheel set, Hardened steel



AFM
Flanged polymer bush, Food grade polymer



D19 D29
Compression springs in metre length steel, by the metre



EPE
Wing nuts Hygienic Design®, Narrow




CHAL3
Piano hinge, Steel



M1
Worm and wheel set, Machined plastic (delrin)




 PTRSS
Idler chain sprocket, For hostile environments



ACL-PLAngle
Joining plate for aluminium profile, Angle connection

 Complementary products



CAB
Stainless steel cable, Stainless steel



ERC
Quick fitting cable terminal, Eye version



RDERSS
Stainless steel manual rigging screw, Stainless steel - manual



CABPVC
PVC covered galvanised steel cable, Galvanised steel with

