

# Stainless steel quick fitting cable terminals Sta

## ERCss ERLss



### Fork and eye versions

- Cable terminals for wires, manual crimping

- Material: Stainless steel 316

#### Advantage

- Rapid manual assembly

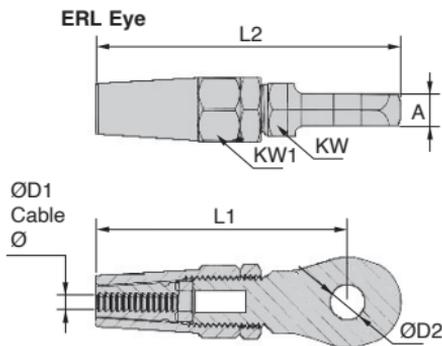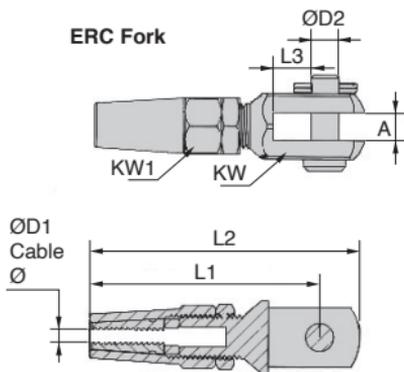

#### DISCOUNTS

Qty	1+	4+	10+	15+
Disc.	List	-10%	-20%	On request

Part number	ØD1	ØD2	A	L1	L2	L3	KW	KW1	Weight (g)	Stock*	Price each 1 to 3
<b>Fork</b>											
ERC3-6/SS	3	6	6,25	49,0	57,0	8,0	12	14	40	✓	37,70 €
ERC4-8/SS	4	8	7,90	60,5	71,4	8,3	14	19	80	✓	46,30 €
ERC5-10/SS	5	10	9,70	69,0	79,0	10,0	16	22	120	-	54,71 €
ERC6-12/SS	6	12	11,00	81,0	93,0	12,0	19	27	210	-	67,69 €
ERC8-14/SS	8	14	13,00	106,0	120,0	15,0	24	30	376	-	90,76 €
<b>Eye</b>											
ERL3-6/SS	3	6	6	48	57	-	10	12	34	✓	39,55 €
ERL4-8/SS	4	8	7	56	69	-	14	14	62	-	45,13 €
ERL5-10/SS	5	10	8	66	82	-	14	16	88	-	53,27 €
ERL6-13/SS	6	13	9	83	100	-	17	19	154	-	65,03 €
ERL8-14/SS	8	14	10	102	123	-	19	24	278	-	85,70 €

\*Depending on availability - Dimensions in mm


# Stainless steel quick fitting threaded cable terminal

Cable terminal with threaded end **ERFss**

- Cable terminals for wires, manual crimping
- Material : Stainless steel 316

## Advantage

- Easy manual assembly

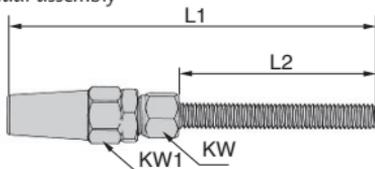

Cable ØD1



## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

Part number	ØD1	ØG	L1	L2	KW	KW1	Weight (g)	Stock*	Price each 1 to 5
ERF3-5-41/SS	3	M5	82	41	10	12	32	✓	42,72 €
ERF3-6-47/SS	3	M6	88	47	10	12	36	✓	42,98 €
ERF4-6-47/SS	4	M6	96	47	12	14	54	✓	47,93 €
ERF4-8-56/SS	4	M8	106	56	12	14	62	-	47,78 €
ERF5-8-56/SS	5	M8	112	56	14	16	84	-	50,59 €
ERF5-10-62/SS	5	M10	118	62	13	16	96	-	55,18 €
ERF6-10-62/SS	6	M10	124	62	16	19	136	-	66,07 €
ERF6-12-79/SS	6	M12	144	79	16	19	164	-	72,64 €
ERF8-14-88/SS	8	M14	168	88	19	24	298	-	96,00 €
ERF8-16-99/SS	8	M16	180	99	19	24	338	-	101,15 €

\*Depending on availability - Dimensions in mm

## Mounting arrangements

