


Sta Quick fitting threaded cable terminal

Cable terminal with threaded end **ERFss**


- Cable terminals for wires, manual crimping
- Material : Stainless steel 316

Advantage

- Easy manual assembly

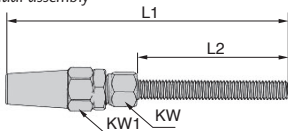

Cable ØD1

 


DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

Part number	ØD1	ØG	L1	L2	KW	KW1	Weight (g)	Stock*	Price each 1 to 5
ERF3-5-41/SS	3	M5	82	41	10	12	32	✓	32,81 €
ERF3-6-47/SS	3	M6	88	47	10	12	36	✓	33,00 €
ERF4-6-47/SS	4	M6	96	47	12	14	54	✓	36,82 €
ERF4-8-56/SS	4	M8	106	56	12	14	62	✓	37,83 €
ERF5-8-56/SS	5	M8	112	56	14	16	84	-	44,15 €
ERF5-10-62/SS	5	M10	118	62	13	16	96	-	44,61 €
ERF6-10-62/SS	6	M10	124	62	16	19	136	-	52,86 €
ERF6-12-79/SS	6	M12	144	79	16	19	164	-	58,72 €
ERF8-14-88/SS	8	M14	168	88	19	24	298	-	80,30 €
ERF8-16-99/SS	8	M16	180	99	19	24	338	-	81,22 €

*Depending on availability - Dimensions in mm

Mounting arrangements

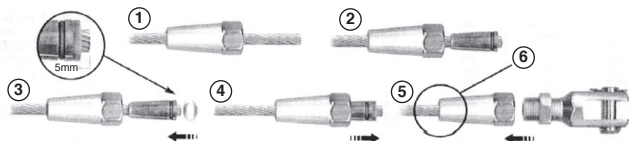

Our other products



CHAL3

Piano hinge,
Aluminium



 
T5P_T10P

Connecting plate for T
type timing belts, T10



Q6

Deep groove ball
bearing, Steel



NANO

Speed controller 3A, 3
A



VRSF

Male swivelling lifting
ring, Male swivelling



SHA_PT

Handwheel with
handle, Polyamide



HTD8M_30

HTD Heavy duty
timing pulley, HTD8
Steel



DB

Steel bevel gear, 2:1



PW_PWG3

Worm - precision
range, Stainless steel



 
BSM

Spring plunger with
internal hexagonal
socket, Steel body,



RPB


Ball screw bearing
unit, Support



PF15

Worm and wheel gear
reducer, up to 3,75
Nm

 Complementary products




CAB

Stainless steel cable,
Stainless steel



ERC

 Quick fitting cable
terminal, Eye version



CAB

Galvanised steel
cable, Galvanised
steel



CABPVC

PVC covered
galvanised steel
cable, Galvanised
steel with

