


Sta Quick fitting threaded cable terminal

Cable terminal with threaded end **ERFss**


- Cable terminals for wires, manual crimping
- Material : Stainless steel 316

Advantage

- Easy manual assembly

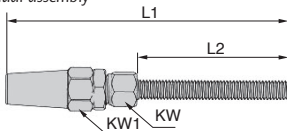

Cable ØD1

 


DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

Part number	ØD1	ØG	L1	L2	KW	KW1	Weight (g)	Stock*	Price each 1 to 5
ERF3-5-41/SS	3	M5	82	41	10	12	32	✓	32,81 €
ERF3-6-47/SS	3	M6	88	47	10	12	36	✓	33,00 €
ERF4-6-47/SS	4	M6	96	47	12	14	54	✓	36,82 €
ERF4-8-56/SS	4	M8	106	56	12	14	62	✓	37,83 €
ERF5-8-56/SS	5	M8	112	56	14	16	84	-	44,15 €
ERF5-10-62/SS	5	M10	118	62	13	16	96	-	44,61 €
ERF6-10-62/SS	6	M10	124	62	16	19	136	-	52,86 €
ERF6-12-79/SS	6	M12	144	79	16	19	164	-	58,72 €
ERF8-14-88/SS	8	M14	168	88	19	24	298	-	80,30 €
ERF8-16-99/SS	8	M16	180	99	19	24	338	-	81,22 €

*Depending on availability - Dimensions in mm

Mounting arrangements

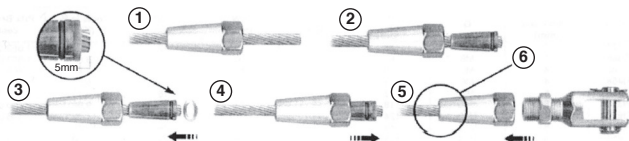

Our other products



HSSss

Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379



HW_HT

Half-rail guide, Rail



PSEC

Security pull handle, Thermoplastic



PRF_BASE

Base plate for aluminium profile, Base plate



ACLRP

Wheel for aluminium profile, Integrated bearing



BAG-MI

Split shaft collar with clamp lever, Steel



SVT20

Screwjack with travelling screw, with translating screw



SDA

Locking bolt support bracket, Mounting holes parallel to locating bolt



KB_WW

Closed linear precision bearing, Economy range



VCMB

Dual-thread screw wood/metal, Stainless steel



GP


Spring loaded toggle latch, With padlock-holder



RJUM05

Drylin R® linear bearing housing, Closed - Long

 Complementary products




CAB

Stainless steel cable, Stainless steel



ERC

 Quick fitting cable terminal, Eye version



CAB

Galvanised steel cable, Galvanised steel



CABPVC

PVC covered galvanised steel cable, Galvanised steel with

