


Sta Quick fitting threaded cable terminal

Cable terminal with threaded end **ERFss**


- Cable terminals for wires, manual crimping
- Material : Stainless steel 316

Advantage

- Easy manual assembly

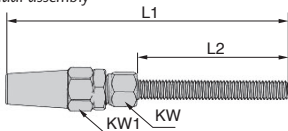

Cable ØD1

 


DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-10%	-20%	On request

Part number	ØD1	ØG	L1	L2	KW	KW1	Weight (g)	Stock*	Price each 1 to 5
ERF3-5-41/SS	3	M5	82	41	10	12	32	✓	32,81 €
ERF3-6-47/SS	3	M6	88	47	10	12	36	✓	33,00 €
ERF4-6-47/SS	4	M6	96	47	12	14	54	✓	36,82 €
ERF4-8-56/SS	4	M8	106	56	12	14	62	✓	37,83 €
ERF5-8-56/SS	5	M8	112	56	14	16	84	-	44,15 €
ERF5-10-62/SS	5	M10	118	62	13	16	96	-	44,61 €
ERF6-10-62/SS	6	M10	124	62	16	19	136	-	52,86 €
ERF6-12-79/SS	6	M12	144	79	16	19	164	-	58,72 €
ERF8-14-88/SS	8	M14	168	88	19	24	298	-	80,30 €
ERF8-16-99/SS	8	M16	180	99	19	24	338	-	81,22 €

*Depending on availability - Dimensions in mm

Mounting arrangements

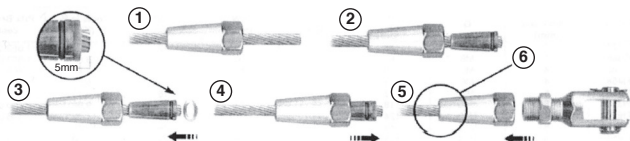


Our other products



PP60

Worm and wheel gear reducer, from 17.80 to 34 Nm

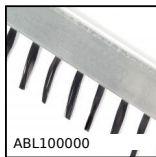

ABL100000

Antistatic brush, For sensitive surfaces



PSG25

Spur gear - precision range, Stainless steel 316



CHM30

Worm and wheel gear reducer, up to 28 Nm




LR

Precision locknut, Precision locknut



NT122

 Spur gear coaxial gearbox, from 32 to 85 Nm - Inline



KSM

Cylindrical steel nut, Steel - 1 thread



PR40

Articulated foot Ø40, Ø 40



FDS

Flexible drive shaft, Masterflex® Steel,



MHWC

Double-disc flexible coupling, Double disk



MDB_MTB

 
Moulded plastic bevel gear (nylon), 3:1



LVT

Miniature motorised actuator 1A, 1 amper

Complementary products




CAB

Stainless steel cable, Stainless steel



ERC

 Quick fitting cable terminal, Eye version



CAB

Galvanised steel cable, Galvanised steel



CABPVC

PVC covered galvanised steel cable, Galvanised steel with

