




- Threaded plate for securing a component using a screw
- Material:  
Steel sheet

### Info

- Sold in packs of 1,000

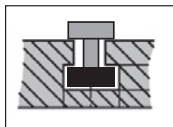

Typical application  
in a T slot

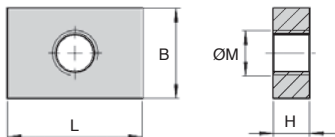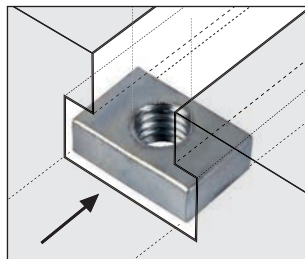


### DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	L	B	H	ØM	Qty per pack	Price each 1 to 4
ERT15-10-4-M5/L	15	10	4	M5	100	28,77 €
ERT15-10-4-M6/L	15	10	4	M6	100	28,77 €
ERT15-10-5-M6/L	15	10	5	M6	100	28,77 €
ERT19-16-4-M4/L	19	16	4	M4	100	31,95 €
ERT19-16-4-M5/L	19	16	4	M5	100	31,95 €
ERT19-16-4-M6/L	19	16	4	M6	100	31,95 €
ERT19-16-4-M8/L	19	16	4	M8	100	31,95 €
ERT19-19-4-M5/L	19	19	4	M5	100	31,95 €
ERT19-19-4-M6/L	19	19	4	M6	100	31,95 €
ERT19-19-4-M8/L	19	19	4	M8	100	31,95 €
ERT20-13-5-M6/L	20	13	5	M6	100	31,95 €
ERT20-13-5-M8/L	20	13	5	M8	100	31,95 €
ERT20-20-4-M4/L	20	20	4	M4	100	35,14 €
ERT20-20-6-M5/L	20	20	6	M5	100	35,14 €
ERT20-20-6-M6/L	20	20	6	M6	100	35,14 €
ERT20-20-6-M8/L	20	20	6	M8	100	35,14 €
ERT25-12-5-M6/L	25	12	5	M6	100	31,95 €

Dimensions in mm
 
## Our other products



BETA

Hitch pin, Hitch



PRF\_RR

Coupling bar for aluminium profile, Coupling bar



HW\_HT

Half-rail guide, Rail



GGB

Female wing knob, With blind thread



CLR

Straight clevis, Straight clevis for use with a male clevis



NTMdl

Set screw delrin tip, Delrin-point



BABreglable

Adjustable ball pin hardened stainless steel, adjustable



Gdal

Double universal joint eco series, Low duty



PRF4545\_P

Stripp Aluminium profile with



PSG15

Spur gear - precision range, Stainless steel



HW\_HT

Half-rail guide, Rail



LR

Precision locknut, Precision locknut

## Complementary products



VTH

Hexagonal headed bolts, Steel class 8.8