




- Threaded plate for securing a component using a screw
- Material:  
Steel sheet

### Info

- Sold in packs of 1,000

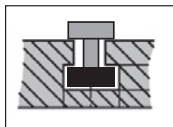

Typical application  
in a T slot

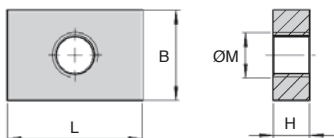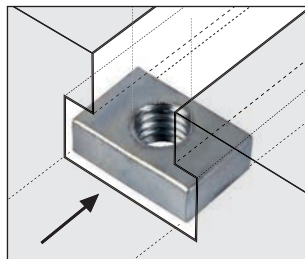

### DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	L	B	H	ØM	Qty per pack	Price each 1 to 4
ERT15-10-4-M5/L	15	10	4	M5	100	28,77 €
ERT15-10-4-M6/L	15	10	4	M6	100	28,77 €
ERT15-10-5-M6/L	15	10	5	M6	100	28,77 €
ERT19-16-4-M4/L	19	16	4	M4	100	31,95 €
ERT19-16-4-M5/L	19	16	4	M5	100	31,95 €
ERT19-16-4-M6/L	19	16	4	M6	100	31,95 €
ERT19-16-4-M8/L	19	16	4	M8	100	31,95 €
ERT19-19-4-M5/L	19	19	4	M5	100	31,95 €
ERT19-19-4-M6/L	19	19	4	M6	100	31,95 €
ERT19-19-4-M8/L	19	19	4	M8	100	31,95 €
ERT20-13-5-M6/L	20	13	5	M6	100	31,95 €
ERT20-13-5-M8/L	20	13	5	M8	100	31,95 €
ERT20-20-4-M4/L	20	20	4	M4	100	35,14 €
ERT20-20-6-M5/L	20	20	6	M5	100	35,14 €
ERT20-20-6-M6/L	20	20	6	M6	100	35,14 €
ERT20-20-6-M8/L	20	20	6	M8	100	35,14 €
ERT25-12-5-M6/L	25	12	5	M6	100	31,95 €

Dimensions in mm

## Our other products




CNA-CNG  
Right angled mounting plate, Right angled mounting plate for ball jo...




PFM  
Fixed levelling foot, Flanged plate



 PM3  
Worm and wheel set, Machined plastic (delrin)




M1  
Worm and wheel set, Machined plastic (delrin)

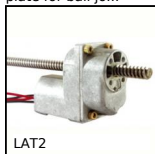

LAT2  
2A motorised linear actuator, 2 amperes



RAM30  
Manual bevel gearbox, Bevel

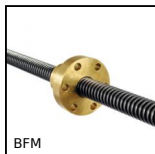

BFM  
Flanged bronze nut, Bronze - 1 thread



MFB\_MHB  
Moulded plastic bevel gear (nylon), 4:1



BPMc  
Stainless steel slotted spring plunger with



PRF\_PF  
Anchoring bracket for aluminium profile,



TBD  
Manual leadscrew table with opposing



BABTV  
Ball lock pins lockable, Stainless steel

## Complementary products



VTH  
Hexagonal headed bolts, Steel class 8.8