




- Threaded plate for securing a component using a screw
- Material:
Steel sheet

Info

- Sold in packs of 1,000

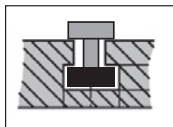

Typical application
in a T slot

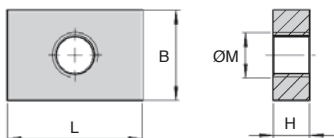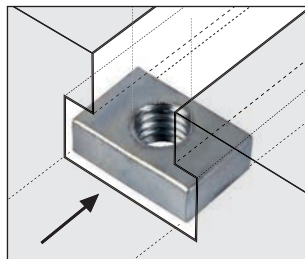

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	L	B	H	ØM	Qty per pack	Price each 1 to 4
ERT15-10-4-M5/L	15	10	4	M5	100	28,77 €
ERT15-10-4-M6/L	15	10	4	M6	100	28,77 €
ERT15-10-5-M6/L	15	10	5	M6	100	28,77 €
ERT19-16-4-M4/L	19	16	4	M4	100	31,95 €
ERT19-16-4-M5/L	19	16	4	M5	100	31,95 €
ERT19-16-4-M6/L	19	16	4	M6	100	31,95 €
ERT19-16-4-M8/L	19	16	4	M8	100	31,95 €
ERT19-19-4-M5/L	19	19	4	M5	100	31,95 €
ERT19-19-4-M6/L	19	19	4	M6	100	31,95 €
ERT19-19-4-M8/L	19	19	4	M8	100	31,95 €
ERT20-13-5-M6/L	20	13	5	M6	100	31,95 €
ERT20-13-5-M8/L	20	13	5	M8	100	31,95 €
ERT20-20-4-M4/L	20	20	4	M4	100	35,14 €
ERT20-20-6-M5/L	20	20	6	M5	100	35,14 €
ERT20-20-6-M6/L	20	20	6	M6	100	35,14 €
ERT20-20-6-M8/L	20	20	6	M8	100	35,14 €
ERT25-12-5-M6/L	25	12	5	M6	100	31,95 €

Dimensions in mm

Our other products



TRMSS

Spur round rack,
Stainless steel -
module 1-5



TOL

Swivel head, Long



DBL880

Idler for slat top
chain, Ranges 880
and 881



GAL_25

Ø25 conveyor roller,
Without ball bearing



BOX-TOR-G

Box set of Nitrile O-
rings in nitrile, 3.00 x
1.50mm to 30.20 x
3.00



PW_PWG15

Worm - precision
range, Stainless steel



 
BAG

Steel Clamping collar,
Steel



RHT

High Temperature
wheel, up to 200kg



TCXR

Automatic chain
tensioner, With
stainless steel
sprocket



FB_ECO

Eco. range steel bevel
gear, 4:1



R203

Die spring ISO10243,
Light



METC

Flanged sintered
bronze bush, Self-
lubricating sintered
bronze

Complementary products



VTH

Hexagonal headed
bolts, Steel class 8.8