


- **Combined bipod support part**
- Component for conveyor structure
- For round tube
- Materials
 - Body: Reinforced polyamide
 - Inserts: Nickel brass
 - Screws: stainless steel

Accessories

- Compatible **PR** Feet



Typical application

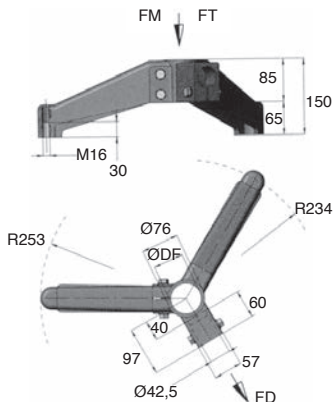

DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDF	Max. load resistance, FM (N)	Max. sliding force FD(N)	Max. working load FT (N)	Weight (kg)	Stock*	Price each 1 to 4
ESCB-42	42,4	13000	7500	7500	1,60	✓	45,70 €
ESCB-48	48,3	13000	7500	8000	1,60	✓	45,70 €
ESCB-50	50,9	13000	7500	8500	1,60	-	46,91 €
ESCB-60	60,3	13000	7500	9000	1,60	-	45,70 €

*Depending on availability - Dimensions in mm

Our other products



SVR5
Screwjack with travelling nut, with moving nut



RVM14
Manual worm and wheel gearbox, Worm/wheel



VBFP
Small 6 lobe threaded handle - female, Duroplast - Brass



DOMI80
Accessories, Clamping lever




Q6
Deep groove ball bearing, Steel



BPPL
Mini plain bearing ball transfer unit, For countersinking



ABL100000
Antistatic brush, For sensitive surfaces

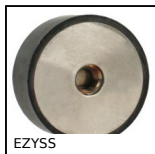

EZYSS
Stainless steel cylindrical stop, stainless steel



DHX
Dowel pin internal thread, Extractable DIN 7979D



KKSS
Rounded end feather key, Stainless steel



SHN
Hexagonal nut DIN934, A2 Stainless steel



PSG3
Spur gear - precision range, Pre-hardened Steel 35NCD6

Complementary products



PR40
Articulated foot Ø40, Ø 40



ESSB
Bipod support base, Bipod support base